


## Screw Thread Micrometer

Item number: 125-112

### Images

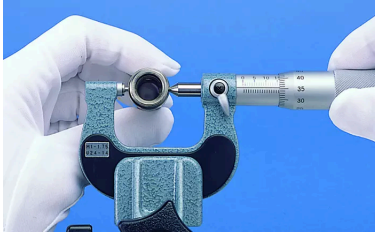

### Description


This Screw Thread Micrometer has a fixed anvil, offering the following benefits:

- Fixed anvil type.
- It directly indicates screw pitch diameter, meaning no need for calculation.

### Features

<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, spanner, setting standard 60°
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	50 - 75 mm
<b>Graduation:</b>	0,01 mm
<b>Spindle feed error:</b>	3 $\mu$ m
<b>Measuring face:</b>	Hardened steel, fixed anvil/spindle
<b>Measuring spindle:</b>	With spindle lock, $\varnothing$ 6,35 mm, spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing$ 18 mm
<b>Thread to be measured (Metric/Unified):</b>	1-1,75 mm / 24-14 TPI
<b>Mass:</b>	260 g

### Dimensions

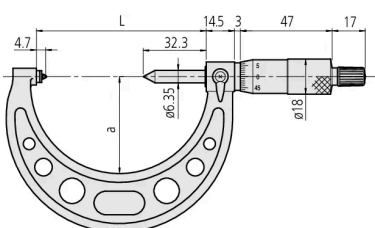

**L:** 87 mm

**a:** 49 mm

### Accessories

Optional accessories:

Promotion!



## Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **55.90 €\***

Suggested retail price: ~~70.00 €\*~~

Standard accessories:



## Setting Standard Screw Thread Micrometer

60°, Length: 50mm

Art No. 167-262

Suggested retail price: 74.00 €\*