

## Screw Thread Micrometer

Item number: 125-116

### Images



### Description


This Screw Thread Micrometer has a fixed anvil, offering the following benefits:

- Fixed anvil type.
- It directly indicates screw pitch diameter, meaning no need for calculation.

### Features

|  |   |
|--|---|
| <b>Digital/Analog:</b>                         | Analog  |
| <b>Delivered:</b>                              | Including box, spanner, setting standard 60°      |
| <b>Inch-Metric:</b>                            | Metric  |
| <b>Range:</b>                                  | 75 - 100 mm                                       |
| <b>Graduation:</b>                             | 0,01 mm   |
| <b>Spindle feed error:</b>                     | 3 μm  |
| <b>Measuring face:</b>                         | Hardened steel, fixed anvil/spindle               |
| <b>Measuring spindle:</b>                      | With spindle lock, ø6,35 mm, spindle pitch 0,5 mm |
| <b>Scale:</b>                                  | Thimble and sleeve satin chrome finish, ø18 mm    |
| <b>Thread to be measured (Metric/Unified):</b> | 0,6-0,9 mm / 44-28 TPI                            |
| <b>Mass:</b>                                   | 330 g   |

### Dimensions

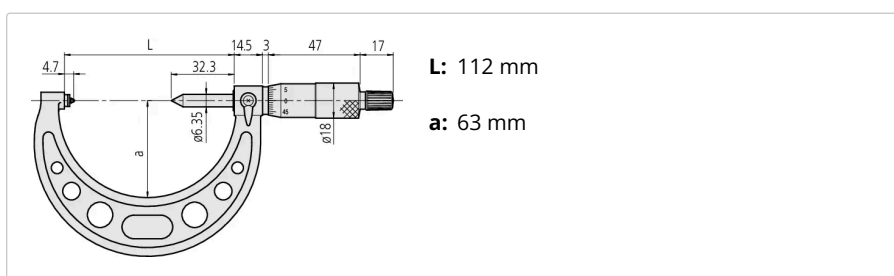

### Accessories

Optional accessories:

Promotion!



## Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **55.90 €\***

Suggested retail price: ~~70.00 €\*~~

Standard accessories:



## Setting Standard Screw Thread Micrometer

60°, Length: 75mm

Art No. 167-263

Suggested retail price: **89.00 €\***