


Screw Thread Micrometer

Item number: 125-117

Images

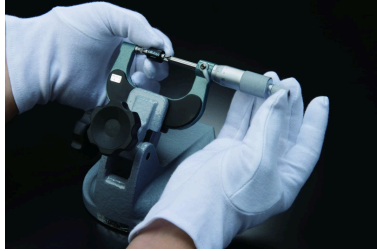

Description


This Screw Thread Micrometer has a fixed anvil, offering the following benefits:

- Fixed anvil type.
- It directly indicates screw pitch diameter, meaning no need for calculation.

Features

Digital/Analog:	Analog
Delivered:	Including box, spanner, setting standard 60°
Inch-Metric:	Metric
Range:	75 - 100 mm
Graduation:	0,01 mm
Spindle feed error:	3 μ m
Measuring face:	Hardened steel, fixed anvil/spindle
Measuring spindle:	With spindle lock, \varnothing 6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, \varnothing 18 mm
Thread to be measured (Metric/Unified):	1-1,75 mm / 24-14 TPI
Mass:	330 g

Dimensions

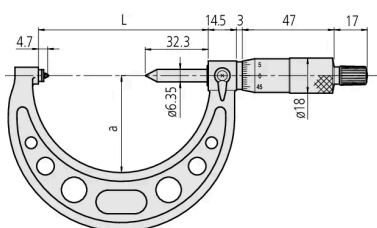

L: 112 mm

a: 63 mm

Accessories

Optional accessories:

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **55.90 €***

Suggested retail price: ~~70.00 €*~~

Standard accessories:



Setting Standard Screw Thread Micrometer

60°, Length: 75mm

Art No. 167-263

Suggested retail price: **89.00 €***