

# Screw Thread Micrometer

Item number: 125-120

## Images



## Description


This Screw Thread Micrometer has a fixed anvil, offering the following benefits:

- Fixed anvil type.
- It directly indicates screw pitch diameter, meaning no need for calculation.

## Features

<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, spanner, setting standard 60°
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	75 - 100 mm
<b>Graduation:</b>	0,01 mm
<b>Spindle feed error:</b>	3 μm
<b>Measuring face:</b>	Hardened steel, fixed anvil/spindle
<b>Measuring spindle:</b>	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø18 mm
<b>Thread to be measured (Metric/Unified):</b>	5,5-7 mm / 4,5-3,5 TPI
<b>Mass:</b>	330 g

## Dimensions

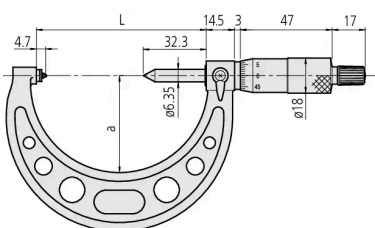

**L:** 112 mm

**a:** 63 mm

## Accessories

Optional accessories:

Promotion!



## Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **55.90 €\***

Suggested retail price: ~~70.00 €\*~~

Standard accessories:



## Setting Standard Screw Thread Micrometer

60°, Length: 75mm

Art No. 167-263

Suggested retail price: **89.00 €\***