


Interchangeable Tip Set (Metric/UNF)

Item number: 126-800

Images

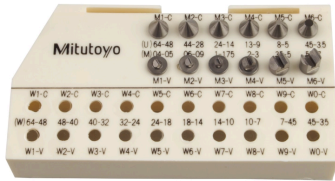

Ø	Thread pitch	Pitch	Ø	Thread pitch	Pitch
Nominal	P	d2	Nominal	P	d2
M 1	0,25	0,838	M 14	2,00	12,701
M 1,2	0,25	1,038	M 16	2,00	14,701
M 1,4	0,30	1,205	M 20	2,50	18,376
M 1,7	0,35	1,473	M 22	2,50	20,376
M 2	0,40	1,740	M 24	3,00	22,051
M 2,3	0,40	2,040	M 27	3,00	25,051
M 2,6	0,45	2,308	M 30	3,50	27,727
M 3	0,50	2,675	M 33	3,50	30,727
M 3,5	0,60	3,110	M 36	4,00	33,402
M 4	0,70	3,545	M 39	4,00	36,402
M 5	0,80	4,480	M 42	4,50	39,077
M 6	1,00	5,350	M 45	4,50	42,077
M 8	1,25	7,188	M 48	5,00	44,752
M 10	1,50	9,026	M 52	5,00	48,752
M 12	1,75	10,863	M 56	5,50	52,428
			M 60	5,50	56,428

Description

A set of matching Mitutoyo anvil and spindle tips to fit Series 126/326 Screw Thread Micrometers to cover the ranges 0,4-7mm pitch Metric and 64-3.5 TPI Unified.

Features

Delivered:	Including rack for interchangeable tips
Content of Set:	No. 126-801 to 126-806
Metric pitch:	0,4 - 7 mm
UNF threads/inch:	64 - 3,5 TPI