


Depth Micrometer

Item number: 128-102

Images

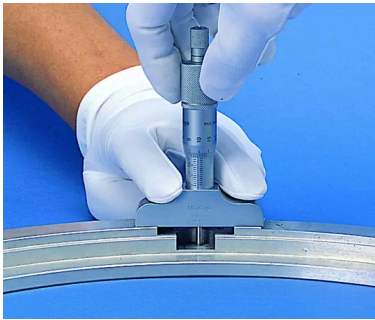

Description

A Mitutoyo non-digital depth micrometer. The 101 mm base is made from tool steel, hardened and ground with a micro-lapped reference surface.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	0 - 25 mm
Graduation:	0,01 mm
Measuring face:	Hardened, precision ground, micro-lap finish
Measuring span:	25 mm
Flatness base:	2 μm
Flatness rod:	0.3 μm
Parallelism base/rod:	5 μm
Base:	Hardened tool steel
Base (W x T):	101.6 x 16 mm
Scale:	Thimble and sleeve satin chrome finish, \varnothing 18 mm
Measuring force:	5-10 N
Mass:	250 g
Delivered:	Including box and spanner 301336

Spindle pitch:

0,5 mm