


Depth Micrometer Carbide Tipped Rod

Item number: 128-103

Images

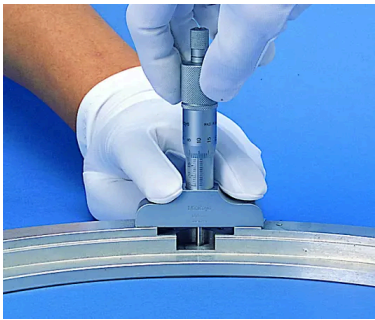

Description

This Depth Micrometer offers you the following benefits:

- $\varnothing 4$ mm measuring rod.
- Ratchet stop provides you with constant measuring force.
- Measuring rod lock.
- Carbide-tipped measuring rod model is available.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	0 - 25 mm
Graduation:	0,01 mm
Measuring face:	Hardened, precision ground, micro-lap finish
Measuring span:	25 mm
Flatness base:	1.3 μm
Flatness rod:	0.3 μm
Parallelism base/rod:	5 μm
Base:	Hardened tool steel
Base (W x T):	63.5 x 16 mm
Scale:	Thimble and sleeve satin chrome finish, \varnothing 18 mm
Measuring force:	5-10 N
Mass:	200 g

Functions:	Carbide-tipped measuring rod
Delivered:	Including box and spanner 301336
Spindle pitch:	0,5 mm