


Depth Micrometer, Interchangeable Rods

Item number: 129-109

Images

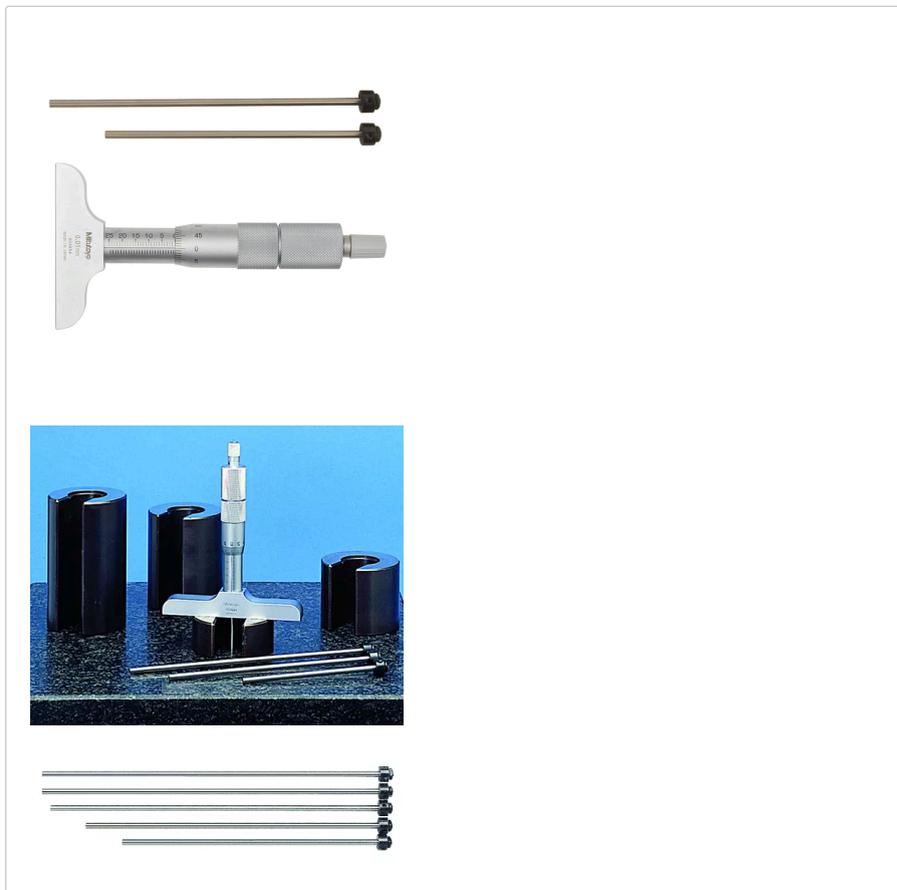

Description

This interchangeable rod type micrometer can be used for wide range measurements. It offers you the following benefits:

- $\varnothing 4$ mm interchangeable rods, with lapped measuring surfaces, enable you to make wide-range measurement.
- The ratchet stop provides constant measuring force.
- Measuring rod lock.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	0 - 50 mm
Graduation:	0,01 mm
Measuring span:	25 mm
Spindle pitch:	0,5 mm
Micrometer Head Feed (0-25 mm):	$\pm 3 \mu\text{m}$
Zero point errors of rods:	$\pm 3 \mu\text{m}$
Flatness base:	1.3 μm
Flatness rod:	0,3 μm
Parallelism base/rod:	5 μm

Measuring face: Hardened, precision ground, micro-lap finish

Base: Hardened tool steel

Number of rods: 2

Scale: Thimble and sleeve satin chrome finish
Ø18 mm


Measuring force: 5-10 N

Functions: Base 63,5 x 16 mm

Mass: 260 g

Delivered: Including box, spanner no. 301336,
04GAA274, hex-spanner no. 202863

Dimensions

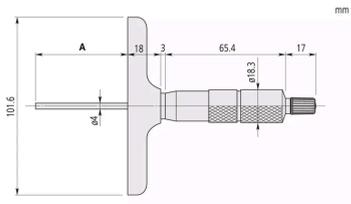

A: 50 mm