


## Depth Micrometer, Interchangeable Rods

Item number: 129-112

### Images

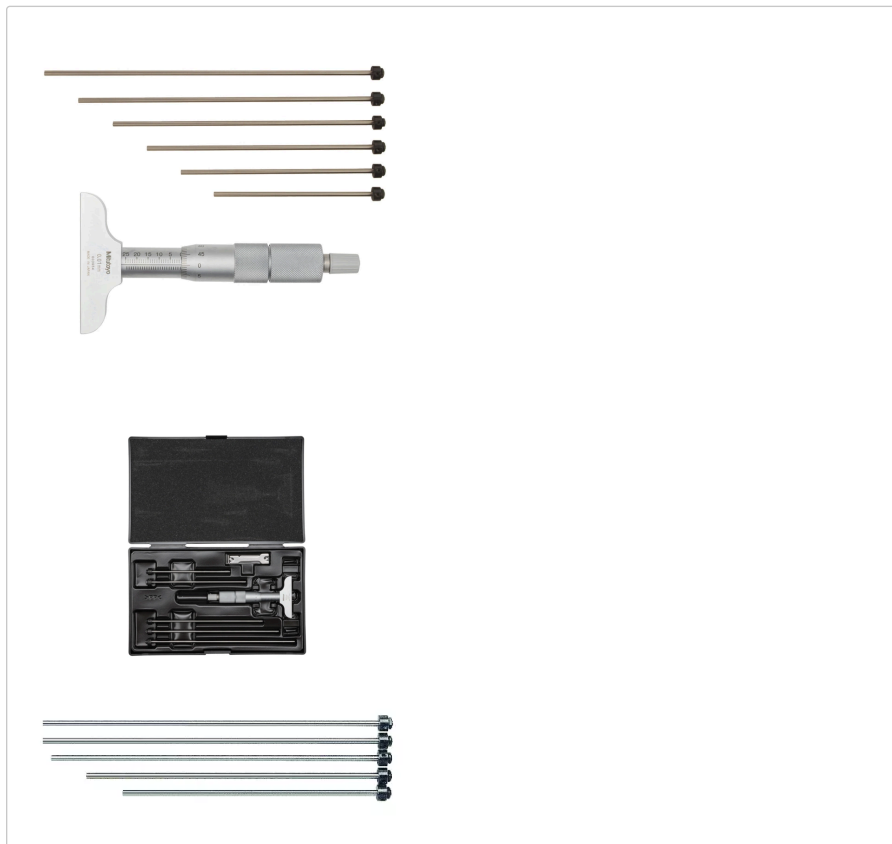

### Description

A non-digital Mitutoyo depth micrometer using interchangeable measuring rods to cover a wide measuring range. The 60mm base is made from tool steel, hardened and ground with a micro-lapped reference surface.

### Features

<b>Inch-Metric:</b>	Metric
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	0 - 150 mm
<b>Graduation:</b>	0,01 mm
<b>Measuring span:</b>	25 mm
<b>Spindle pitch:</b>	0,5 mm
<b>Micrometer Head Feed (0-25 mm):</b>	$\pm 3 \mu\text{m}$
<b>Zero point errors of rods:</b>	$\pm 4 \mu\text{m}$
<b>Flatness base:</b>	1.3 $\mu\text{m}$
<b>Flatness rod:</b>	0,3 $\mu\text{m}$
<b>Parallelism base/rod:</b>	7 $\mu\text{m}$
<b>Measuring face:</b>	Hardened, precision ground, micro-lap finish
<b>Base:</b>	Hardened tool steel
<b>Number of rods:</b>	6

**Scale:** Thimble and sleeve satin chrome finish  
Ø18 mm


**Measuring force:** 5-10 N

**Functions:** Base 63,5 x 16 mm

**Mass:** 370 g

**Delivered:** Including box, spanner no. 301336,  
04GAA274, hex-spanner no. 202863

## Dimensions

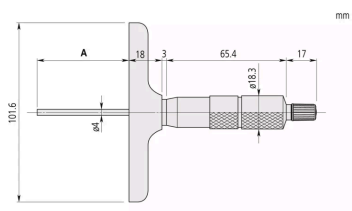

**A:** 150 mm