


## Depth Micrometer, Interchangeable Rods

Item number: 129-114

### Images

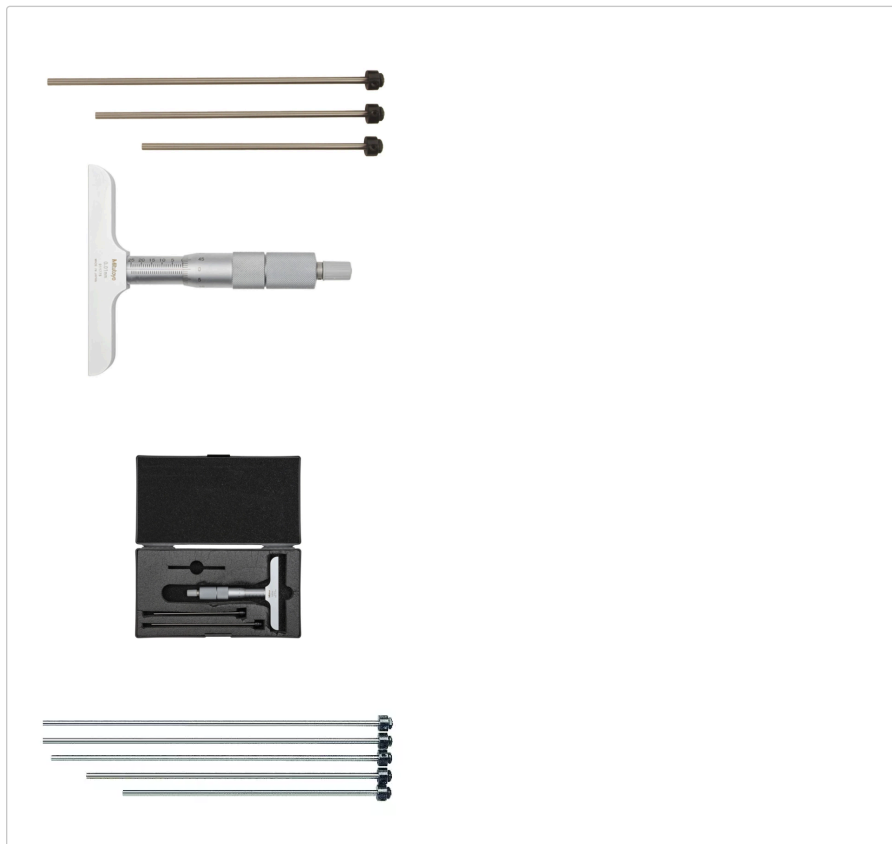

### Description

This interchangeable rod type micrometer can be used for wide range measurements. It offers you the following benefits:

- $\varnothing 4$  mm interchangeable rods, with lapped measuring surfaces, enable you to make wide-range measurement.
- The ratchet stop provides constant measuring force.
- Measuring rod lock.

### Features

<b>Inch-Metric:</b>	Metric
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	0 - 75 mm
<b>Graduation:</b>	0,01 mm
<b>Measuring span:</b>	25 mm
<b>Spindle pitch:</b>	0,5 mm
<b>Micrometer Head Feed (0-25 mm):</b>	$\pm 3 \mu\text{m}$
<b>Zero point errors of rods:</b>	$\pm 3 \mu\text{m}$
<b>Flatness base:</b>	2 $\mu\text{m}$
<b>Flatness rod:</b>	0,3 $\mu\text{m}$
<b>Parallelism base/rod:</b>	6 $\mu\text{m}$
<b>Measuring face:</b>	Hardened, precision ground, micro-lap finish

<b>Base:</b>	Hardened tool steel
<b>Number of rods:</b>	3
<b>Scale:</b>	Thimble and sleeve satin chrome finish Ø18 mm
<b>Measuring force:</b>	5-10 N
<b>Delivered:</b>	Including box, spanner no. 301336, 04GAA274, hex-spanner no. 202863
<b>Mass:</b>	330 g

**Dimensions**

