


Depth Micrometer, Interchangeable Rods

Item number: 129-115

Images

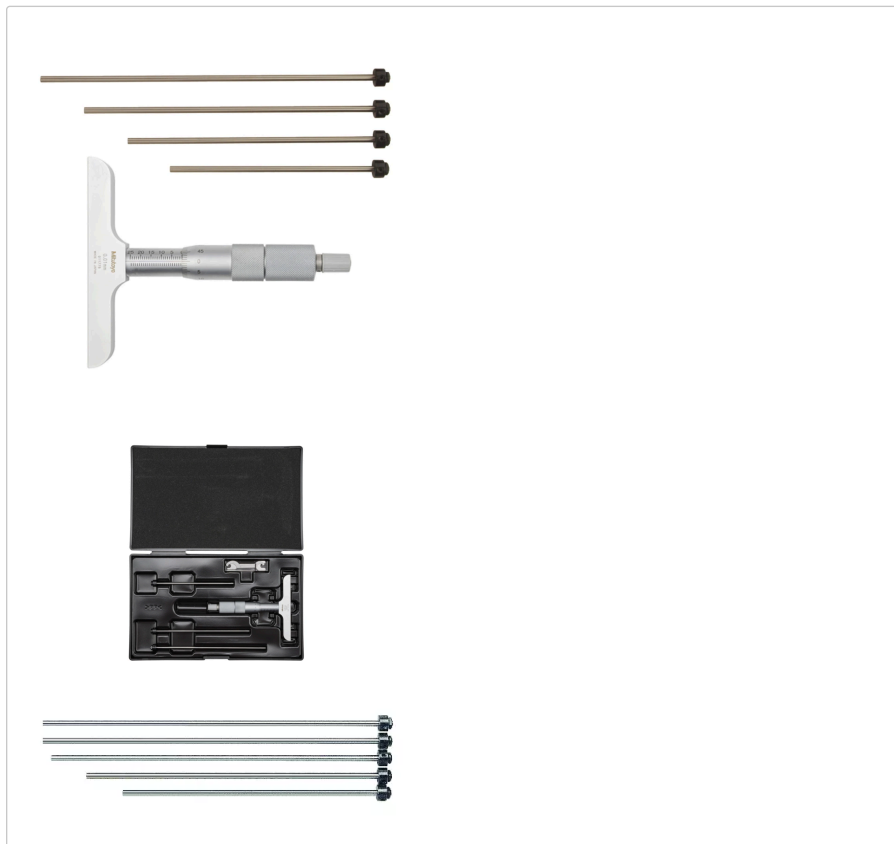

Description

This interchangeable rod type micrometer can be used for wide range measurements. It offers you the following benefits:

- $\varnothing 4$ mm interchangeable rods, with lapped measuring surfaces, enable you to make wide-range measurement.
- The ratchet stop provides constant measuring force.
- Measuring rod lock.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	0 - 100 mm
Graduation:	0,01 mm
Measuring span:	25 mm
Spindle pitch:	0,5 mm
Micrometer Head Feed (0-25 mm):	$\pm 3 \mu\text{m}$
Zero point errors of rods:	$\pm 4 \mu\text{m}$
Flatness base:	$2 \mu\text{m}$
Flatness rod:	$0,3 \mu\text{m}$
Parallelism base/rod:	$6 \mu\text{m}$
Measuring face:	Hardened, precision ground, micro-lap finish

Base:	Hardened tool steel
Number of rods:	4
Scale:	Thimble and sleeve satin chrome finish Ø18 mm
Measuring force:	5-10 N
Functions:	Base 101,6 x 16 mm
Mass:	355 g
Delivered:	Including box, spanner no. 301336, 04GAA274, hex-spanner no. 202863

Dimensions

