


Depth Micrometer, Interchangeable Rods

Item number: 129-127

Images

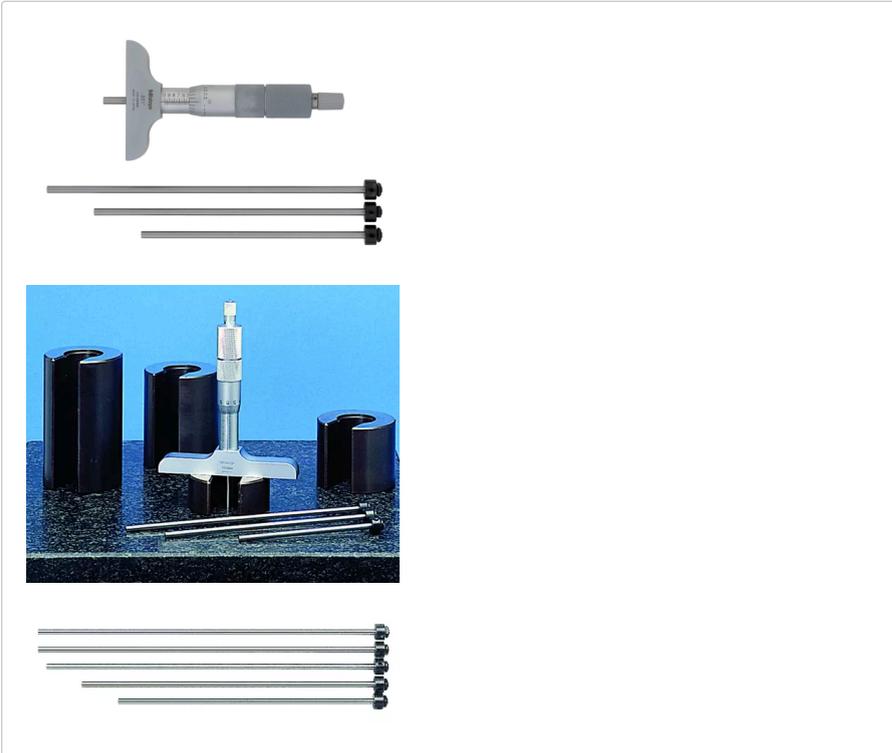

Description

This interchangeable rod type micrometer can be used for wide range measurements. It offers you the following benefits:

- $\varnothing 4$ mm interchangeable rods, with lapped measuring surfaces, enable you to make wide-range measurement.
- The ratchet stop provides constant measuring force.
- Measuring rod lock.

Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Graduation:	0,001"
Range:	0 - 4 "
Measuring span:	25 mm
Spindle pitch:	0,5 mm
Micrometer Head Feed (0-25 mm):	$\pm 3 \mu\text{m}$
Zero point errors of rods:	$\pm 4 \mu\text{m}$ (0-150 mm) $\pm 6 \mu\text{m}$ (0-300 mm)
Parallelism base/rod:	$(4 + L/50) \mu\text{m}$ L=max. measuring length (mm)
Measuring face:	Hardened, precision ground, micro-lap finish
Base:	Hardened tool steel
Number of rods:	4

Scale:	Thimble and sleeve satin chrome finish Ø18 mm
---------------	--

Measuring force:	5-10 N
-------------------------	--------

Functions:	Base 2.5 x 0.63"
-------------------	------------------

Mass:	310 g
--------------	-------

Delivered:	Including box, spanner no. 301336, 04GAA274, hex-spanner no. 202863
-------------------	--