


Depth Micrometer, Interchangeable Rods

Item number: 129-132

Images

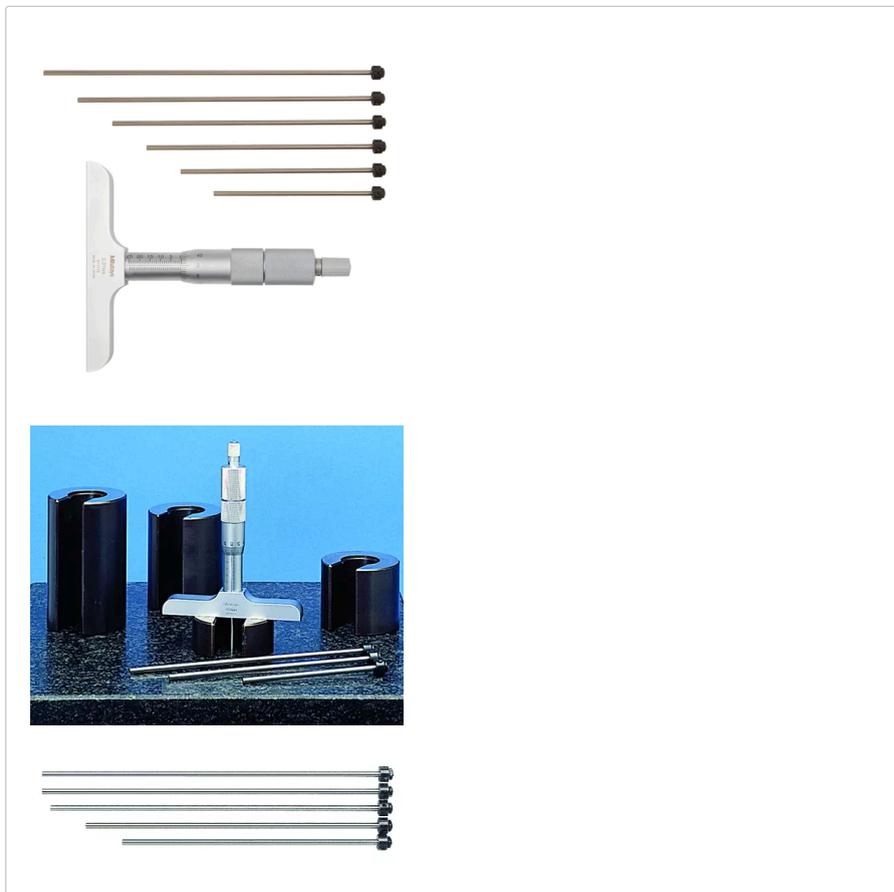

Description

A Mitutoyo non-digital depth micrometer using interchangeable measuring rods to cover a wide measuring range. The base is made from tool steel, hardened and ground with a micro-lapped reference surface.

Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Graduation:	0,001"
Range:	0 - 6 "
Measuring span:	25 mm
Spindle pitch:	0,5 mm
Micrometer Head Feed (0-25 mm):	±3 μm
Zero point errors of rods:	±4 μm (0-150 mm) ±6 μm (0-300 mm)
Parallelism base/rod:	(4+ L/50) μm L=max. measuring length (mm)
Measuring face:	Hardened, precision ground, micro-lap finish
Base:	Hardened tool steel
Number of rods:	6

Scale:	Thimble and sleeve satin chrome finish Ø18 mm
---------------	--

Measuring force:	5-10 N
-------------------------	--------

Functions:	Base 4 x 0.63"
-------------------	----------------

Mass:	410 g
--------------	-------

Delivered:	Including box, spanner no. 301336, 04GAA274, hex-spanner no. 202863
-------------------	--