


## Depth Micrometer, Interchangeable Rods

Item number: 129-153

### Images

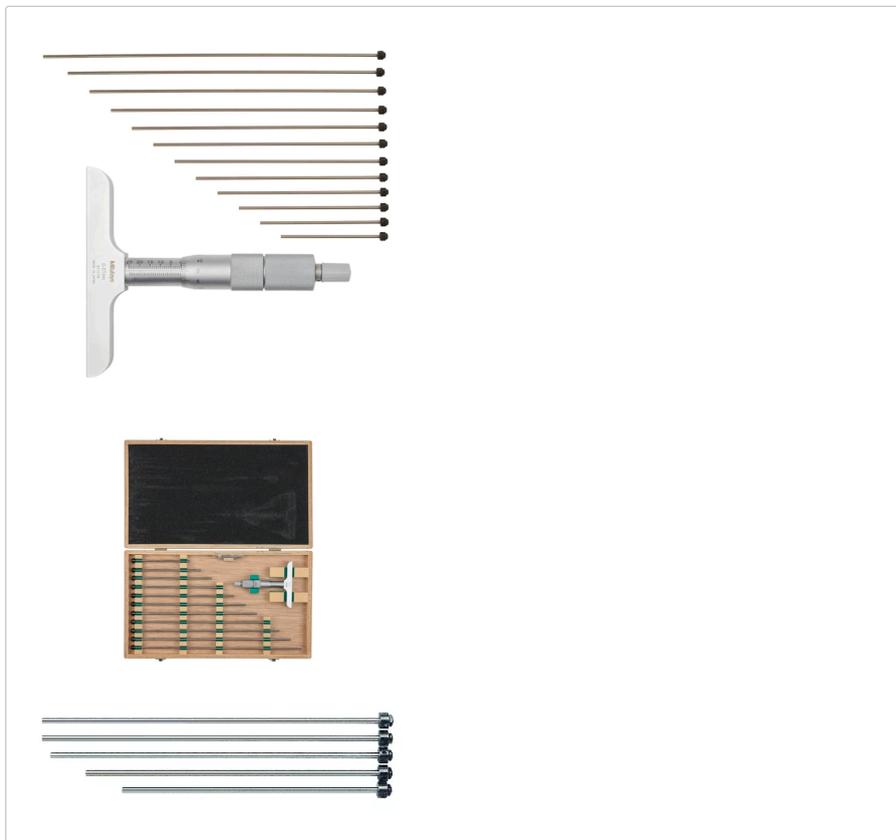

### Description

A Mitutoyo non-digital depth micrometer using interchangeable measuring rods to cover a wide measuring range. The 100mm base is made from tool steel, hardened and ground with a micro-lapped reference surface.

### Features

<b>Inch-Metric:</b>	Metric
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	0 - 300 mm
<b>Graduation:</b>	0,01 mm
<b>Measuring span:</b>	25 mm
<b>Spindle pitch:</b>	0,5 mm
<b>Micrometer Head Feed (0-25 mm):</b>	$\pm 3 \mu\text{m}$
<b>Zero point errors of rods:</b>	$\pm 6 \mu\text{m}$
<b>Flatness base:</b>	$2 \mu\text{m}$
<b>Flatness rod:</b>	$0,3 \mu\text{m}$
<b>Parallelism base/rod:</b>	$10 \mu\text{m}$
<b>Measuring face:</b>	Hardened, precision ground, micro-lap finish
<b>Base:</b>	Hardened tool steel
<b>Number of rods:</b>	12


**Scale:** Thimble and sleeve satin chrome finish  
Ø18 mm

**Measuring force:** 5-10 N

**Delivered:** Including box, spanner no. 301336,  
04GAA274, hex-spanner no. 202863

**Mass:** 640 g

## Dimensions

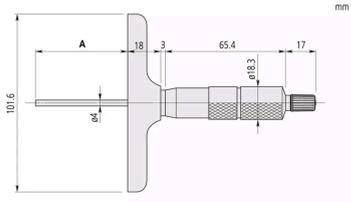

**A:** 300 mm