

Probe Extension Holder, Height Gauge

Item number: 12AAA793

Images




Description

Mitutoyo Probe Extension Holder (85mm/ 3.3").

Features

Remarks: Delivered without measuring insert

Dimensions

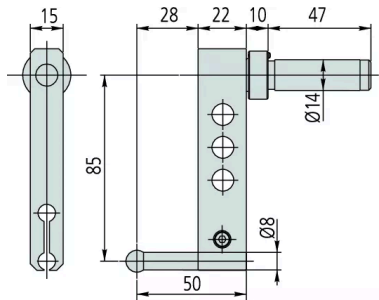

Accessories

Optional accessories:



Ball Probe Coaxial Type

D=1mm, 72mm Length

Art No. 12AAF666

Suggested retail price: 201.00 €*

Ball Probe Coaxial Type

D=2mm, 72mm Length

Art No. 957261

Suggested retail price: **114.00 €***



Ball Probe Coaxial Type

D=2mm, Ruby, 72mm Length

Art No. 12AAF667

Suggested retail price: **319.00 €***



Ball Probe Coaxial Type

D=3mm, 72mm Length

Art No. 957262

Suggested retail price: **120.00 €***



Ball Probe Coaxial Type

D=4mm, 76mm Length

Art No. 957263

Suggested retail price: **132.00 €***



Ball Probe, Coaxial Type

D=10mm

Art No. 12AAB552

Suggested retail price: **185.00 €***



Ball Probe Coaxial Type

D=10mm, 82mm Length
Art No. 12AAF668
Suggested retail price: 230.00 €*




Ball Probe Coaxial Type

D=10mm, 120mm Length
Art No. 12AAF669
Suggested retail price: 251.00 €*




Disk Probe Coaxial Type

D=5mm, 75mm Length
Art No. 12AAF670
Suggested retail price: 222.00 €*




Disk Probe Coaxial Type

D=10mm, 59mm Length
Art No. 12AAF671
Suggested retail price: 177.00 €*




Disk Probe Coaxial Type

D=14mm, 59mm Length
Art No. 957264
Suggested retail price: 234.00 €*




Disk Probe Coaxial Type

D=20mm, 48mm Length
Art No. 957265
Suggested retail price: 293.00 €*




Disk Stylus, Coaxial Type

D=25mm, 99,5mm Length
Art No. 12AAY598
Suggested retail price: 193.00 €*




Ball Probe Eccentric Type

D=1mm
Art No. 12AAF672
Suggested retail price: 179.00 €*




Ball Probe Eccentric Type

D=2mm
Art No. 12AAF673
Suggested retail price: 240.00 €*




Ball Probe Eccentric Type

D=4mm
Art No. 12AAA788
Suggested retail price: 81.00 €*






Ball Probe Eccentric Type

D=6mm

Art No. 12AAA789

Suggested retail price: **87.00 €***



Stylus, Eccentric Type

D=5mm, 130mm Length

Art No. 12AAY597

Suggested retail price: **519.00 €***



CMM Stylus Adapter M2

Art No. 226117

Suggested retail price: **57.00 €***



CMM Stylus Adapter M3

Art No. 226118

Suggested retail price: **57.00 €***



Depth Stylus for Height Gauge

for max. 70mm Depth

Art No. 12AAY599

Suggested retail price: **135.00 €***

Depth Stylus for Height Gauge

for max. 150mm Depth

Art No. 12AAY600

Suggested retail price: **155.00 €***



Depth Stylus for Height Gauge

for max. 300mm Depth

Art No. 12AAY601

Suggested retail price: **155.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 70mm Depth, D=2mm Ball

Art No. 12AAY602

Suggested retail price: **231.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 150mm Depth, D=2mm Ball

Art No. 12AAY603

Suggested retail price: **250.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 300mm Depth, D=2mm Ball

Art No. 12AAY604

Suggested retail price: **250.00 €***





Depth Stylus for Height Gauge

Offset Type, for max. 70mm Depth, D=4mm Ball

Art No. 12AAY605

Suggested retail price: **213.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 150mm Depth, D=4mm Ball

Art No. 12AAY606

Suggested retail price: **213.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 300mm Depth, D=4mm Ball

Art No. 12AAY607

Suggested retail price: **231.00 €***



Extension Holder, 100mm

for Height Gauge

Art No. 12AAY595

Suggested retail price: **270.00 €***



Extension Holder, 200mm

for Height Gauge

Art No. 12AAY596

Suggested retail price: **310.00 €***



Depth Probe for Height Gauge

90mm Reach

Art No. 12AAC072

Suggested retail price: 201.00 €*
[View product](#)



Indicator Holder LH-600

For 8mm Stem

Art No. 12AAA792

Suggested retail price: 134.00 €*
[View product](#)



Probe Extension Holder, Height Gauge

85mm

Art No. 12AAA793

Suggested retail price: 134.00 €*
[View product](#)



Tapered Measuring Insert

D=22mm

Art No. 12AAC073

Suggested retail price: 161.00 €*
[View product](#)



Setting Block Linear Height/QM-Height

Probe Calibration and Taper Probe

Art No. 12AAA787

Suggested retail price: 287.00 €*
[View product](#)




Cylindrical Probe

D=10mm

Art No. 12AAB136

Suggested retail price: 292.00 €*
Suggested retail price: 292.00 €*
Suggested retail price: 292.00 €*

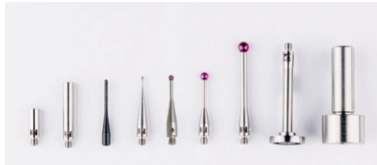

Stylus Kit M3 for Linear Height

with Holder, 5 Probes, 2 Extensions, 1 Dowel-key

Art No. K650986

Suggested retail price: 452.00 €*
Suggested retail price: 452.00 €*



Power Cable CEE Type

for Europe (except UK)

Art No. 02ZAA021

Suggested retail price: 7.70 €*
Suggested retail price: 7.70 €*



Printer Paper

Serie 518, LH-600, 10 Rolls

Art No. 12AAN052

Suggested retail price: 224.00 €*
Suggested retail price: 224.00 €*



U-WAVE-T Transmitter Mounting Plate

for LH-600F/FG

Art No. 12AAY486

Suggested retail price: 51.00 €*
Suggested retail price: 51.00 €*



USB Cable

A-Type 2m

Art No. 12BAF812

Suggested retail price: 18.50 €*
~~18.50 €~~

Promotion!



Connection Cable D for U-WAVE

Flat 10-Pin Type

Art No. 02AZD790D

Promo price: 68.00 €*
~~98.00 €~~

Suggested retail price: 98.00 €*
~~98.00 €~~

Promotion!



Connection Cable SF for U-WAVE

for U-WAVE-T and Instruments with
Digimatic S1 Interface

Art No. 02AZG011

Promo price: 86.00 €*
~~131.00 €~~

Suggested retail price: 131.00 €*
~~131.00 €~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat 10-Pin
Type

Art No. 06AFM380D

Promo price: 98.00 €*
~~124.00 €~~

Suggested retail price: 124.00 €*
~~124.00 €~~



Digimatic Cable, Straight, 1m

Digimatic/Digimatic 2/Digimatic S1 Interface,
1 m

Art No. 06AGL011

Suggested retail price: 79.00 €*
~~79.00 €~~



Digimatic Cable, Straight, 2m

Digimatic/Digimatic 2/Digimatic S1 Interface,
2 m

Art No. 06AGL021

Suggested retail price: **84.00 €***

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2/Digimatic
S1 Interface

Art No. 06AGQ001F

Promo price: **129.00 €***

Suggested retail price: ~~164.00 €*~~



AC-Adapter, DC 6V 2A

CEE version Germany (Europe)

Art No. 06AGZ369D

Suggested retail price: **85.00 €***



AC-Adapter, 6V 2A

Korea

Art No. 06AGZ369E

Suggested retail price: **85.00 €***



Digimatic Cable, Flat 10-Pin Type

1 m

Art No. 936937

Suggested retail price: **57.00 €***



Digimatic Cable, Flat 10-Pin Type

2 m

Art No. 965014

Suggested retail price: 72.00 €*

Promotion!



USB Input Tool Interface Box

Digimatic/Digimatic 2/Digimatic S1 Interface

Art No. 264-020

Promo price: 204.00 €*

Suggested retail price: 259.00 €*

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: 129.00 €*

Suggested retail price: 187.00 €*

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: 129.00 €*

Suggested retail price: 187.00 €*



U-WAVE Transmitter Mounting Plate

for QM-Height

Art No. 02AZE990

Suggested retail price: 43.00 €*

Promotion!



U-WAVE-R Wireless Receiver

Based on IEEE802.15.4 (2,4 GHz)

Art No. 02AZD810D

Promo price: **249.00 €***

Suggested retail price: ~~371.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-626

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-627

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~



USB Cable 1m, DP-1VA to PC etc.

USB Type A to Micro USB Type B Plug

Art No. 06AFZ050

Suggested retail price: **21.00 €***