


Ball Probe Coaxial Type

Item number: 12AAF666

Images

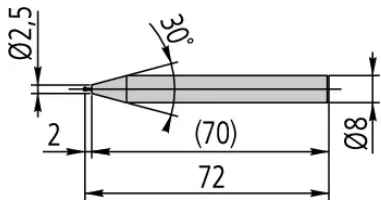

Description

Mitutoyo Coaxial Ø1mm Ball Probe.

Features

Remarks:

With 8 mm stem

Accessories

Optional accessories:



Ball Probe Coaxial Type

D=1mm, 72mm Length
Art No. 12AAF666
Suggested retail price: 201.00 €*



Ball Probe Coaxial Type

D=2mm, 72mm Length
Art No. 957261
Suggested retail price: 114.00 €*



Ball Probe Coaxial Type

D=2mm, Ruby, 72mm Length
Art No. 12AAF667
Suggested retail price: 319.00 €*



Ball Probe Coaxial Type

D=3mm, 72mm Length
Art No. 957262
Suggested retail price: 120.00 €*

Ball Probe Coaxial Type

D=4mm, 76mm Length

Art No. 957263

Suggested retail price: **132.00 €***



Ball Probe, Coaxial Type

D=10mm

Art No. 12AAB552

Suggested retail price: **185.00 €***



Ball Probe Coaxial Type

D=10mm, 82mm Length

Art No. 12AAF668

Suggested retail price: **230.00 €***



Ball Probe Coaxial Type

D=10mm, 120mm Length

Art No. 12AAF669

Suggested retail price: **251.00 €***



Disk Probe Coaxial Type

D=5mm, 75mm Length

Art No. 12AAF670

Suggested retail price: **222.00 €***



Disk Probe Coaxial Type

D=10mm, 59mm Length
Art No. 12AAF671
Suggested retail price: 177.00 €*



Disk Probe Coaxial Type

D=14mm, 59mm Length
Art No. 957264
Suggested retail price: 234.00 €*



Disk Probe Coaxial Type

D=20mm, 48mm Length
Art No. 957265
Suggested retail price: 293.00 €*



Disk Stylus, Coaxial Type


D=25mm, 99,5mm Length
Art No. 12AAY598
Suggested retail price: 193.00 €*



Ball Probe Eccentric Type

D=1mm
Art No. 12AAF672
Suggested retail price: 179.00 €*



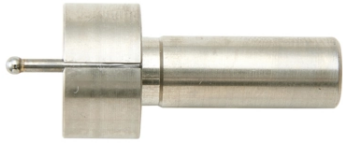

Ball Probe Eccentric Type

D=2mm

Art No. 12AAF673

Suggested retail price: 240.00 €*
€* = Excl. VAT



Ball Probe Eccentric Type

D=4mm

Art No. 12AAA788

Suggested retail price: 81.00 €*
€* = Excl. VAT



Ball Probe Eccentric Type

D=6mm

Art No. 12AAA789

Suggested retail price: 87.00 €*
€* = Excl. VAT



Stylus, Eccentric Type

D=5mm, 130mm Length

Art No. 12AAY597

Suggested retail price: 519.00 €*
€* = Excl. VAT



CMM Stylus Adapter M2

Art No. 226117

Suggested retail price: 57.00 €*
€* = Excl. VAT



CMM Stylus Adapter M3

Art No. 226118

Suggested retail price: **57.00 €***



Depth Stylus for Height Gauge

for max. 70mm Depth

Art No. 12AAY599

Suggested retail price: **135.00 €***



Depth Stylus for Height Gauge

for max. 150mm Depth

Art No. 12AAY600

Suggested retail price: **155.00 €***



Depth Stylus for Height Gauge

for max. 300mm Depth

Art No. 12AAY601

Suggested retail price: **155.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 70mm Depth, D=2mm Ball

Art No. 12AAY602

Suggested retail price: **231.00 €***

Depth Stylus for Height Gauge



Offset Type, for max. 150mm Depth,
D=2mm Ball

Art No. 12AAY603

Suggested retail price: **250.00 €***

Depth Stylus for Height Gauge



Offset Type, for max. 300mm Depth,
D=2mm Ball

Art No. 12AAY604

Suggested retail price: **250.00 €***

Depth Stylus for Height Gauge



Offset Type, for max. 70mm Depth, D=4mm
Ball

Art No. 12AAY605

Suggested retail price: **213.00 €***

Depth Stylus for Height Gauge



Offset Type, for max. 150mm Depth,
D=4mm Ball

Art No. 12AAY606

Suggested retail price: **213.00 €***

Depth Stylus for Height Gauge



Offset Type, for max. 300mm Depth,
D=4mm Ball

Art No. 12AAY607

Suggested retail price: **231.00 €***

Extension Holder, 100mm

for Height Gauge
Art No. 12AAY595
Suggested retail price: 270.00 €*



Extension Holder, 200mm

for Height Gauge
Art No. 12AAY596
Suggested retail price: 310.00 €*



Depth Probe for Height Gauge

90mm Reach
Art No. 12AAC072
Suggested retail price: 201.00 €*



Indicator Holder LH-600

For 8mm Stem
Art No. 12AAA792
Suggested retail price: 134.00 €*



Probe Extension Holder, Height Gauge

85mm
Art No. 12AAA793
Suggested retail price: 134.00 €*





Tapered Measuring Insert

D=22mm

Art No. 12AAC073

Suggested retail price: **161.00 €***



Setting Block Linear Height/QM-Height

Probe Calibration and Taper Probe

Art No. 12AAA787

Suggested retail price: **287.00 €***




Cylindrical Probe

D=10mm

Art No. 12AAB136

Suggested retail price: **292.00 €***

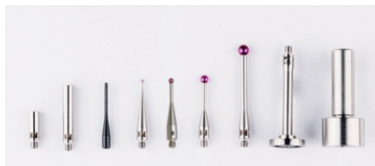

Stylus Kit M3 for Linear Height

with Holder, 5 Probes, 2 Extensions, 1 Dowel-key

Art No. K650986

Suggested retail price: **452.00 €***



Power Cable CEE Type

for Europe (except UK)

Art No. 02ZAA021

Suggested retail price: **7.70 €***



Printer Paper

Serie 518, LH-600, 10 Rolls
Art No. 12AAN052
Suggested retail price: **224.00 €***



U-WAVE-T Transmitter Mounting Plate

for LH-600F/FG
Art No. 12AAY486
Suggested retail price: **51.00 €***



USB Cable

A-Type 2m
Art No. 12BAF812
Suggested retail price: **18.50 €***

Promotion!



Connection Cable D for U- WAVE

Flat 10-Pin Type
Art No. 02AZD790D
Promo price: 68.00 €*
~~Suggested retail price: 98.00 €*~~

Promotion!



Connection Cable SF for U- WAVE

for U-WAVE-T and Instruments with
Digimatic S1 Interface
Art No. 02AZG011
Promo price: 86.00 €*
~~Suggested retail price: 131.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat 10-Pin
Type

Art No. 06AFM380D

Promo price: **98.00 €***

Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Straight, 1m

Digimatic/Digimatic 2/Digimatic S1 Interface,
1 m

Art No. 06AGL011

Suggested retail price: **79.00 €***



Digimatic Cable, Straight, 2m

Digimatic/Digimatic 2/Digimatic S1 Interface,
2 m

Art No. 06AGL021

Suggested retail price: **84.00 €***

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2/Digimatic
S1 Interface

Art No. 06AGQ001F

Promo price: **129.00 €***

Suggested retail price: ~~164.00 €*~~



AC-Adapter, DC 6V 2A

CEE version Germany (Europe)

Art No. 06AGZ369D

Suggested retail price: **85.00 €***



AC-Adapter, 6V 2A

Korea

Art No. 06AGZ369E

Suggested retail price: **85.00 €***



Digimatic Cable, Flat 10-Pin Type

1 m

Art No. 936937

Suggested retail price: **57.00 €***



Digimatic Cable, Flat 10-Pin Type

2 m

Art No. 965014

Suggested retail price: **72.00 €***

Promotion!



USB Input Tool Interface Box

Digimatic/Digimatic 2/Digimatic S1 Interface

Art No. 264-020

Promo price: **204.00 €***

Suggested retail price: ~~259.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~



U-WAVE Transmitter Mounting Plate

for QM-Height

Art No. 02AZE990

Suggested retail price: **43.00 €***

Promotion!



U-WAVE-R Wireless Receiver

Based on IEEE802.15.4 (2,4 GHz)

Art No. 02AZD810D

Promo price: **249.00 €***

Suggested retail price: ~~371.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for

Micrometer/Indicator

Art No. 264-626

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for

Micrometer/Indicator

Art No. 264-627

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~



USB Cable 1m, DP-1VA to PC etc.

USB Type A to Micro USB Type B Plug

Art No. 06AFZ050

Suggested retail price: **21.00 €***