

Ball Probe Coaxial Type

Item number: 12AAF669

Images



Description

 
Mitutoyo Coaxial \varnothing 10mm Ball Probe, L=120mm.

Features

Remarks:

With 8 mm stem

Dimensions



Accessories

Optional accessories:



Ball Probe Coaxial Type

D=1mm, 72mm Length

Art No. 12AAF666

Suggested retail price: 201.00 €*



Ball Probe Coaxial Type

D=2mm, 72mm Length

Art No. 957261

Suggested retail price: 114.00 €*



Ball Probe Coaxial Type

D=2mm, Ruby, 72mm Length

Art No. 12AAF667

Suggested retail price: 319.00 €*



Ball Probe Coaxial Type

D=3mm, 72mm Length

Art No. 957262

Suggested retail price: 120.00 €*

Ball Probe Coaxial Type

D=4mm, 76mm Length
Art No. 957263
Suggested retail price: 132.00 €*



Ball Probe, Coaxial Type

D=10mm
Art No. 12AAB552
Suggested retail price: 185.00 €*



Ball Probe Coaxial Type

D=10mm, 82mm Length
Art No. 12AAF668
Suggested retail price: 230.00 €*



Ball Probe Coaxial Type

D=10mm, 120mm Length
Art No. 12AAF669
Suggested retail price: 251.00 €*



Disk Probe Coaxial Type

D=5mm, 75mm Length
Art No. 12AAF670
Suggested retail price: 222.00 €*



Disk Probe Coaxial Type

D=10mm, 59mm Length
Art No. 12AAF671
Suggested retail price: 177.00 €*



Disk Probe Coaxial Type

D=14mm, 59mm Length
Art No. 957264
Suggested retail price: 234.00 €*



Disk Probe Coaxial Type

D=20mm, 48mm Length
Art No. 957265
Suggested retail price: 293.00 €*



Disk Stylus, Coaxial Type

D=25mm, 99,5mm Length
Art No. 12AAY598
Suggested retail price: 193.00 €*



Ball Probe Eccentric Type

D=1mm
Art No. 12AAF672
Suggested retail price: 179.00 €*



Ball Probe Eccentric Type



D=2mm
Art No. 12AAF673
Suggested retail price: 240.00 €*

Ball Probe Eccentric Type



D=4mm
Art No. 12AAA788
Suggested retail price: 81.00 €*

Ball Probe Eccentric Type



D=6mm
Art No. 12AAA789
Suggested retail price: 87.00 €*

Stylus, Eccentric Type



D=5mm, 130mm Length
Art No. 12AAY597
Suggested retail price: 519.00 €*

CMM Stylus Adapter M2



Art No. 226117
Suggested retail price: 57.00 €*



CMM Stylus Adapter M3

Art No. 226118

Suggested retail price: 57.00 €*



Depth Stylus for Height Gauge

for max. 70mm Depth

Art No. 12AAY599

Suggested retail price: 135.00 €*



Depth Stylus for Height Gauge

for max. 150mm Depth

Art No. 12AAY600

Suggested retail price: 155.00 €*



Depth Stylus for Height Gauge

for max. 300mm Depth

Art No. 12AAY601

Suggested retail price: 155.00 €*



Depth Stylus for Height Gauge

Offset Type, for max. 70mm Depth, D=2mm
Ball

Art No. 12AAY602

Suggested retail price: 231.00 €*

Depth Stylus for Height Gauge

Offset Type, for max. 150mm Depth,
D=2mm Ball

Art No. 12AAY603

Suggested retail price: 250.00 €*



Depth Stylus for Height Gauge

Offset Type, for max. 300mm Depth,
D=2mm Ball

Art No. 12AAY604

Suggested retail price: 250.00 €*



Depth Stylus for Height Gauge

Offset Type, for max. 70mm Depth, D=4mm
Ball

Art No. 12AAY605

Suggested retail price: 213.00 €*



Depth Stylus for Height Gauge

Offset Type, for max. 150mm Depth,
D=4mm Ball

Art No. 12AAY606

Suggested retail price: 213.00 €*



Depth Stylus for Height Gauge

Offset Type, for max. 300mm Depth,
D=4mm Ball

Art No. 12AAY607

Suggested retail price: 231.00 €*



Extension Holder, 100mm

for Height Gauge
Art No. 12AAY595
Suggested retail price: 270.00 €*



Extension Holder, 200mm

for Height Gauge
Art No. 12AAY596
Suggested retail price: 310.00 €*



Depth Probe for Height Gauge

90mm Reach
Art No. 12AAC072
Suggested retail price: 201.00 €*



Indicator Holder LH-600

For 8mm Stem
Art No. 12AAA792
Suggested retail price: 134.00 €*



Probe Extension Holder, Height Gauge

85mm
Art No. 12AAA793
Suggested retail price: 134.00 €*





Tapered Measuring Insert

D=22mm
Art No. 12AAC073
Suggested retail price: 161.00 €*




Setting Block Linear Height/QM-Height

Probe Calibration and Taper Probe
Art No. 12AAA787
Suggested retail price: 287.00 €*



Cylindrical Probe

D=10mm
Art No. 12AAB136
Suggested retail price: 292.00 €*

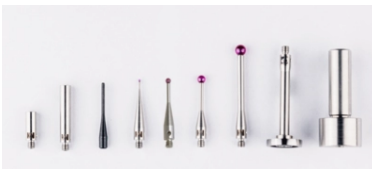

Stylus Kit M3 for Linear Height

with Holder, 5 Probes, 2 Extensions, 1 Dowel-key
Art No. K650986
Suggested retail price: 452.00 €*



Power Cable CEE Type

for Europe (except UK)
Art No. 02ZAA021
Suggested retail price: 7.70 €*



Printer Paper

Serie 518, LH-600, 10 Rolls
Art No. 12AAN052
Suggested retail price: 224.00 €*



U-WAVE-T Transmitter Mounting Plate

for LH-600F/FG
Art No. 12AAY486
Suggested retail price: 51.00 €*



USB Cable

A-Type 2m
Art No. 12BAF812
Suggested retail price: 18.50 €*

Promotion!



Connection Cable D for U- WAVE

Flat 10-Pin Type
Art No. 02AZD790D
Promo price: **68.00 €***
Suggested retail price: 98.00 €*

Promotion!



Connection Cable SF for U- WAVE

for U-WAVE-T and Instruments with
Digimatic S1 Interface
Art No. 02AZG011
Promo price: **86.00 €***
Suggested retail price: 131.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat 10-Pin Type

Art No. 06AFM380D

Promo price: **98.00 €***

Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Straight, 1m

Digimatic/Digimatic 2/Digimatic S1 Interface, 1 m

Art No. 06AGL011

Suggested retail price: 79.00 €*



Digimatic Cable, Straight, 2m

Digimatic/Digimatic 2/Digimatic S1 Interface, 2 m

Art No. 06AGL021

Suggested retail price: 84.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2/Digimatic S1 Interface

Art No. 06AGQ001F

Promo price: **129.00 €***

Suggested retail price: ~~164.00 €*~~



AC-Adapter, DC 6V 2A

CEE version Germany (Europe)

Art No. 06AGZ369D

Suggested retail price: 85.00 €*



AC-Adapter, 6V 2A

Korea
Art No. 06AGZ369E
Suggested retail price: 85.00 €*



Digimatic Cable, Flat 10-Pin Type

1 m
Art No. 936937
Suggested retail price: 57.00 €*



Digimatic Cable, Flat 10-Pin Type

2 m
Art No. 965014
Suggested retail price: 72.00 €*

Promotion!



USB Input Tool Interface Box

Digimatic/Digimatic 2/Digimatic S1 Interface
Art No. 264-020
Promo price: **204.00 €***
~~Suggested retail price: 259.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €***
~~Suggested retail price: 187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~



U-WAVE Transmitter Mounting Plate

for QM-Height
Art No. 02AZE990
Suggested retail price: **43.00 €***

Promotion!



U-WAVE-R Wireless Receiver

Based on IEEE802.15.4 (2,4 GHz)
Art No. 02AZD810D
Promo price: **249.00 €***
Suggested retail price: ~~371.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626
Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627
Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~



**USB Cable 1m, DP-1VA to PC
etc.**

USB Type A to Micro USB Type B Plug

Art No. 06AFZ050

Suggested retail price: 21.00 €*
