

Battery Pack

Item number: 12AAF712

Images



Description

Mitutoyo provide this battery pack for the Linear Height High Performance Height Gauge.

Features

Remarks:	Standard battery pack
----------	-----------------------

Accessories

Ball Probe Coaxial Type



D=1mm, 72mm Length
Art No. 12AAF666
Suggested retail price: 201.00 €*
[View product](#)

Ball Probe Coaxial Type



D=2mm, 72mm Length
Art No. 957261
Suggested retail price: 114.00 €*
[View product](#)

Ball Probe Coaxial Type



D=2mm, Ruby, 72mm Length
Art No. 12AAF667
Suggested retail price: 319.00 €*
[View product](#)

Ball Probe Coaxial Type



D=3mm, 72mm Length
Art No. 957262
Suggested retail price: 120.00 €*
[View product](#)

Ball Probe Coaxial Type



D=4mm, 76mm Length
Art No. 957263
Suggested retail price: 132.00 €*
[View product](#)

Ball Probe, Coaxial Type



D=10mm

Art No. 12AAB552

Suggested retail price: **185.00 €***

Ball Probe Coaxial Type



D=10mm, 82mm Length

Art No. 12AAF668

Suggested retail price: **230.00 €***

Ball Probe Coaxial Type



D=10mm, 120mm Length

Art No. 12AAF669

Suggested retail price: **251.00 €***

Disk Probe Coaxial Type



D=5mm, 75mm Length

Art No. 12AAF670

Suggested retail price: **222.00 €***

Disk Probe Coaxial Type



D=10mm, 59mm Length

Art No. 12AAF671

Suggested retail price: **177.00 €***

Disk Probe Coaxial Type

D=14mm, 59mm Length
Art No. 957264
Suggested retail price: 234.00 €*



Disk Probe Coaxial Type

D=20mm, 48mm Length
Art No. 957265
Suggested retail price: 293.00 €*



Disk Stylus, Coaxial Type

D=25mm, 99,5mm Length
Art No. 12AAY598
Suggested retail price: 193.00 €*



Ball Probe Eccentric Type

D=1mm
Art No. 12AAF672
Suggested retail price: 179.00 €*



Ball Probe Eccentric Type

D=2mm
Art No. 12AAF673
Suggested retail price: 240.00 €*



Ball Probe Eccentric Type



D=4mm

Art No. 12AAA788

Suggested retail price: **81.00 €***

Ball Probe Eccentric Type



D=6mm

Art No. 12AAA789

Suggested retail price: **87.00 €***

Stylus, Eccentric Type



D=5mm, 130mm Length

Art No. 12AAY597

Suggested retail price: **519.00 €***

CMM Stylus Adapter M2



Art No. 226117

Suggested retail price: **57.00 €***

CMM Stylus Adapter M3



Art No. 226118

Suggested retail price: **57.00 €***

Depth Stylus for Height Gauge

for max. 70mm Depth
Art No. 12AAY599
Suggested retail price: **135.00 €***



Depth Stylus for Height Gauge

for max. 150mm Depth
Art No. 12AAY600
Suggested retail price: **155.00 €***



Depth Stylus for Height Gauge

for max. 300mm Depth
Art No. 12AAY601
Suggested retail price: **155.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 70mm Depth, D=2mm
Ball
Art No. 12AAY602
Suggested retail price: **231.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 150mm Depth,
D=2mm Ball
Art No. 12AAY603
Suggested retail price: **250.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 300mm Depth,
D=2mm Ball

Art No. 12AAY604

Suggested retail price: **250.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 70mm Depth, D=4mm
Ball

Art No. 12AAY605

Suggested retail price: **213.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 150mm Depth,
D=4mm Ball

Art No. 12AAY606

Suggested retail price: **213.00 €***



Depth Stylus for Height Gauge

Offset Type, for max. 300mm Depth,
D=4mm Ball

Art No. 12AAY607

Suggested retail price: **231.00 €***



Extension Holder, 100mm

for Height Gauge

Art No. 12AAY595

Suggested retail price: **270.00 €***



Extension Holder, 200mm

for Height Gauge
Art No. 12AAY596
Suggested retail price: 310.00 €*




Depth Probe for Height Gauge

90mm Reach
Art No. 12AAC072
Suggested retail price: 201.00 €*




Indicator Holder LH-600

For 8mm Stem
Art No. 12AAA792
Suggested retail price: 134.00 €*




Probe Extension Holder, Height Gauge

85mm
Art No. 12AAA793
Suggested retail price: 134.00 €*




Tapered Measuring Insert

D=22mm
Art No. 12AAC073
Suggested retail price: 161.00 €*





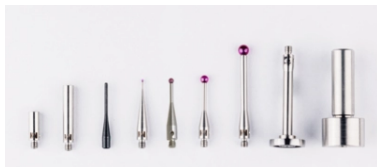

Setting Block Linear Height/QM-Height

Probe Calibration and Taper Probe
Art No. 12AAA787
Suggested retail price: 287.00 €*
[View product](#)



Cylindrical Probe

D=10mm
Art No. 12AAB136
Suggested retail price: 292.00 €*
[View product](#)



Stylus Kit M3 for Linear Height

with Holder, 5 Probes, 2 Extensions, 1 Dowel-key
Art No. K650986
Suggested retail price: 452.00 €*
[View product](#)



Power Cable CEE Type

for Europe (except UK)
Art No. 02ZAA021
Suggested retail price: 7.70 €*
[View product](#)



Receipt Printer for LH-600F/FG

CEE Type
Art No. 12AAY483
Suggested retail price: 1,499.00 €*
[View product](#)



Printer Paper

Serie 518, LH-600, 10 Rolls
Art No. 12AAN052
Suggested retail price: **118.00 €***



U-WAVE-T Transmitter Mounting Plate

for LH-600F/FG
Art No. 12AAY486
Suggested retail price: **51.00 €***



USB Cable

A-Type 2m
Art No. 12BAF812
Suggested retail price: **18.50 €***

Promotion!



Connection Cable D for U- WAVE

Flat 10-Pin Type
Art No. 02AZD790D
Promo price: 63.90 €*
~~Suggested retail price: 98.00 €*~~

Promotion!



Connection Cable SF for U- WAVE

for U-WAVE-T and Instruments with
Digimatic S1 Interface
Art No. 02AZG011
Promo price: 109.00 €*
~~Suggested retail price: 131.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat 10-Pin
Type

Art No. 06AFM380D

Promo price: **98.90 €***

Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Straight, 1m

Digimatic/Digimatic 2/Digimatic S1 Interface

Art No. 06AGL011

Suggested retail price: **79.00 €***



Digimatic Cable, Straight, 2m

Digimatic/Digimatic 2/Digimatic S1 Interface

Art No. 06AGL021

Suggested retail price: **84.00 €***

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2/Digimatic
S1 Interface

Art No. 06AGQ001F

Promo price: **129.00 €***

Suggested retail price: ~~164.00 €*~~



AC-Adapter, DC 6V 2A

CEE version Germany (Europe)

Art No. 06AGZ369D

Suggested retail price: **85.00 €***



AC-Adapter, 6V 2A

Korea

Art No. 06AGZ369E

Suggested retail price: **85.00 €***



Digimatic Cable, Flat 10-Pin Type

1 m

Art No. 936937

Suggested retail price: **57.00 €***



Digimatic Cable, Flat 10-Pin Type

2 m

Art No. 965014

Suggested retail price: **72.00 €***

Promotion!



USB Input Tool Interface Box

Digimatic/Digimatic 2/Digimatic S1 Interface

Art No. 264-020

Promo price: **209.00 €***

Suggested retail price: ~~259.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~



U-WAVE Transmitter Mounting Plate

for QM-Height

Art No. 02AZE990

Suggested retail price: **43.00 €***

Promotion!



U-WAVE-R Wireless Receiver

Based on IEEE802.15.4 (2,4 GHz)

Art No. 02AZD810D

Promo price: **249.00 €***

Suggested retail price: ~~371.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for

Micrometer/Indicator

Art No. 264-626

Promo price: **139.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for

Micrometer/Indicator

Art No. 264-627

Promo price: **139.00 €***

Suggested retail price: ~~185.00 €*~~



USB Cable 1m, DP-1VA to PC etc.

USB Type A to Micro USB Type B Plug

Art No. 06AFZ050

Suggested retail price: **21.00 €***