

Depth Stylus for Height Gauge

Item number: 12AAY606


Images



Description

Depth Stylus Offset Type, for max. 150mm Depth, Ø4mm Ball

Dimensions

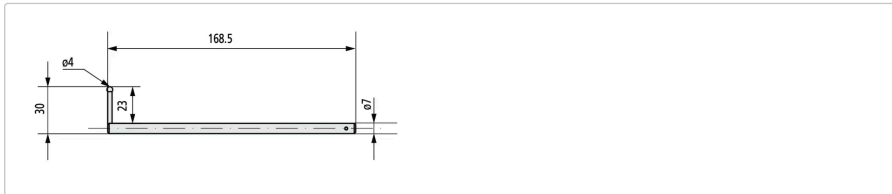

Accessories

Optional accessories:



Ball Probe Coaxial Type

D=1mm, 72mm Length

Art No. 12AAF666

Suggested retail price: 201.00 €*



Ball Probe Coaxial Type

D=2mm, 72mm Length

Art No. 957261

Suggested retail price: 114.00 €*

Ball Probe Coaxial Type

D=2mm, Ruby, 72mm Length
Art No. 12AAF667
Suggested retail price: 319.00 €*



Ball Probe Coaxial Type

D=3mm, 72mm Length
Art No. 957262
Suggested retail price: 120.00 €*



Ball Probe Coaxial Type

D=4mm, 76mm Length
Art No. 957263
Suggested retail price: 132.00 €*



Ball Probe, Coaxial Type

D=10mm
Art No. 12AAB552
Suggested retail price: 185.00 €*



Ball Probe Coaxial Type

D=10mm, 82mm Length
Art No. 12AAF668
Suggested retail price: 230.00 €*



Ball Probe Coaxial Type

D=10mm, 120mm Length
Art No. 12AAF669
Suggested retail price: 251.00 €*



Disk Probe Coaxial Type

D=5mm, 75mm Length
Art No. 12AAF670
Suggested retail price: 222.00 €*



Disk Probe Coaxial Type

D=10mm, 59mm Length
Art No. 12AAF671
Suggested retail price: 177.00 €*



Disk Probe Coaxial Type

D=14mm, 59mm Length
Art No. 957264
Suggested retail price: 234.00 €*



Disk Probe Coaxial Type

D=20mm, 48mm Length
Art No. 957265
Suggested retail price: 293.00 €*



Disk Stylus, Coaxial Type

D=25mm, 99,5mm Length
Art No. 12AAY598
Suggested retail price: 193.00 €*




Ball Probe Eccentric Type

D=1mm
Art No. 12AAF672
Suggested retail price: 179.00 €*



Ball Probe Eccentric Type

D=2mm
Art No. 12AAF673
Suggested retail price: 240.00 €*

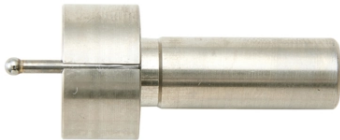

Ball Probe Eccentric Type

D=4mm
Art No. 12AAA788
Suggested retail price: 81.00 €*



Ball Probe Eccentric Type

D=6mm
Art No. 12AAA789
Suggested retail price: 87.00 €*



Stylus, Eccentric Type

D=5mm, 130mm Length
Art No. 12AAY597
Suggested retail price: 519.00 €*



CMM Stylus Adapter M2

Art No. 226117
Suggested retail price: 57.00 €*



CMM Stylus Adapter M3

Art No. 226118
Suggested retail price: 57.00 €*



Depth Stylus for Height Gauge

for max. 70mm Depth
Art No. 12AAY599
Suggested retail price: 135.00 €*




Depth Stylus for Height Gauge

 
for max. 150mm Depth
Art No. 12AAY600
Suggested retail price: 155.00 €*




Depth Stylus for Height Gauge

for max. 300mm Depth
Art No. 12AAY601
Suggested retail price: 155.00 €*



Depth Stylus for Height Gauge

Offset Type, for max. 70mm Depth, D=2mm
Ball
Art No. 12AAY602
Suggested retail price: 231.00 €*


Depth Stylus for Height Gauge

Offset Type, for max. 150mm Depth,
D=2mm Ball
Art No. 12AAY603
Suggested retail price: 250.00 €*


Depth Stylus for Height Gauge

Offset Type, for max. 300mm Depth,
D=2mm Ball
Art No. 12AAY604
Suggested retail price: 250.00 €*


Depth Stylus for Height Gauge

Offset Type, for max. 70mm Depth, D=4mm
Ball
Art No. 12AAY605
Suggested retail price: 213.00 €*


Depth Stylus for Height Gauge

Offset Type, for max. 150mm Depth,
D=4mm Ball

Art No. 12AAY606

Suggested retail price: 213.00 €*



Depth Stylus for Height Gauge

Offset Type, for max. 300mm Depth,
D=4mm Ball

Art No. 12AAY607

Suggested retail price: 231.00 €*



Extension Holder, 100mm

for Height Gauge

Art No. 12AAY595

Suggested retail price: 270.00 €*



Extension Holder, 200mm

for Height Gauge

Art No. 12AAY596

Suggested retail price: 310.00 €*



Depth Probe for Height Gauge

90mm Reach

Art No. 12AAC072

Suggested retail price: 201.00 €*





Indicator Holder LH-600

For 8mm Stem
Art No. 12AAA792
Suggested retail price: 134.00 €*



Probe Extension Holder, Height Gauge

85mm
Art No. 12AAA793
Suggested retail price: 134.00 €*



Tapered Measuring Insert

D=22mm
Art No. 12AAC073
Suggested retail price: 161.00 €*



Setting Block Linear Height/QM-Height

Probe Calibration and Taper Probe
Art No. 12AAA787
Suggested retail price: 287.00 €*



Cylindrical Probe

D=10mm
Art No. 12AAB136
Suggested retail price: 292.00 €*



Stylus Kit M3 for Linear Height

with Holder, 5 Probes, 2 Extensions, 1 Dowel-key
Art No. K650986
Suggested retail price: 452.00 €*



Power Cable CEE Type

for Europe (except UK)
Art No. 02ZAA021
Suggested retail price: 7.70 €*



Receipt Printer for LH-600F/FG

CEE Type
Art No. 12AAY483
Suggested retail price: 1,499.00 €*



Printer Paper

Serie 518, LH-600, 10 Rolls
Art No. 12AAN052
Suggested retail price: 118.00 €*



U-WAVE-T Transmitter Mounting Plate

for LH-600F/FG
Art No. 12AAY486
Suggested retail price: 51.00 €*

USB Cable

A-Type 2m

Art No. 12BAF812

Suggested retail price: 18.50 €*
Photo Not Available



Promotion!



Connection Cable D for U-WAVE

Flat 10-Pin Type

Art No. 02AZD790D

Promo price: **63.90 €***

Suggested retail price: 98.00 €*
Photo Not Available

Promotion!



Connection Cable SF for U-WAVE

for U-WAVE-T and Instruments with Digimatic S1 Interface

Art No. 02AZG011

Promo price: **109.00 €***

Suggested retail price: 131.00 €*
Photo Not Available

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat 10-Pin Type

Art No. 06AFM380D

Promo price: **98.90 €***

Suggested retail price: 124.00 €*
Photo Not Available



Digimatic Cable, Straight, 1m

Digimatic/Digimatic 2/Digimatic S1 Interface

Art No. 06AGL011

Suggested retail price: 79.00 €*
Photo Not Available



Digimatic Cable, Straight, 2m

Digimatic/Digimatic 2/Digimatic S1 Interface
Art No. 06AGL021
Suggested retail price: 84.00 €*
~~129.00 €* (crossed out)~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2/Digimatic
S1 Interface
Art No. 06AGQ001F
Promo price: **129.00 €* (in red)**
Suggested retail price: ~~164.00 €* (crossed out)~~



AC-Adapter, DC 6V 2A

CEE version Germany (Europe)
Art No. 06AGZ369D
Suggested retail price: 85.00 €*
~~129.00 €* (crossed out)~~



AC-Adapter, 6V 2A

Korea
Art No. 06AGZ369E
Suggested retail price: 85.00 €*
~~129.00 €* (crossed out)~~



Digimatic Cable, Flat 10-Pin Type

1 m
Art No. 936937
Suggested retail price: 57.00 €*
~~129.00 €* (crossed out)~~



Digimatic Cable, Flat 10-Pin Type

2 m

Art No. 965014

Suggested retail price: 72.00 €*
~~72.00 €*~~

Promotion!



USB Input Tool Interface Box

Digimatic/Digimatic 2/Digimatic S1 Interface

Art No. 264-020

Promo price: **209.00 €***
~~259.00 €*~~

Suggested retail price: 259.00 €*
~~259.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***
~~187.00 €*~~

Suggested retail price: 187.00 €*
~~187.00 €*~~

Promotion!




U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***
~~187.00 €*~~

Suggested retail price: 187.00 €*
~~187.00 €*~~

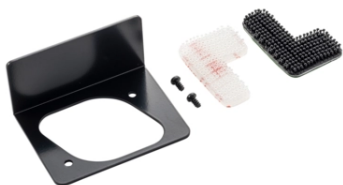

U-WAVE Transmitter Mounting Plate

for QM-Height

Art No. 02AZE990

Suggested retail price: 43.00 €*
~~43.00 €*~~

Promotion!



U-WAVE-R Wireless Receiver

Based on IEEE802.15.4 (2,4 GHz)

Art No. 02AZD810D

Promo price: **249.00 €***

Suggested retail price: ~~371.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-626

Promo price: **139.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-627

Promo price: **139.00 €***

Suggested retail price: ~~185.00 €*~~



USB Cable 1m, DP-1VA to PC etc.

USB Type A to Micro USB Type B Plug

Art No. 06AFZ050

Suggested retail price: **21.00 €***