


Tubular Inside Micrometer

Item number: 133-144

Images

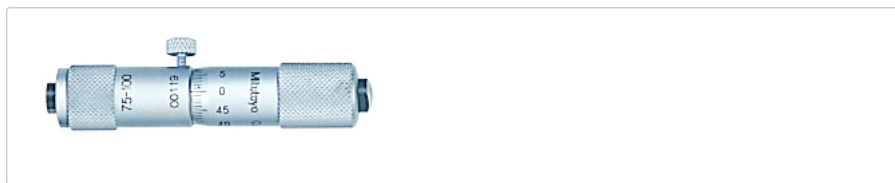

Description

This is a standard single rod type inside micrometer (individual unit), with the following features:

- Standard single rod.
- Carbide measuring faces.

Features

| | |
|--------------------------------------|---|
| Inch-Metric: | Metric |
| Digital/Analog: | Analog |
| Range: | 75 - 100 mm |
| Graduation: | 0.01mm |
| Max. Permissible Error J MPE: | $\pm 4 \mu\text{m}$ |
| Scale: | Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$ |
| Measuring spindle: | With spindle lock (except 50-75 mm), spindle pitch 0,5 mm |
| Measuring face: | Carbide tipped |
| Measuring method: | 2-point |
| Delivered: | Including box and spanner |
| Mass: | 75 g |