


Tubular Inside Micrometer

Item number: 133-228

Images

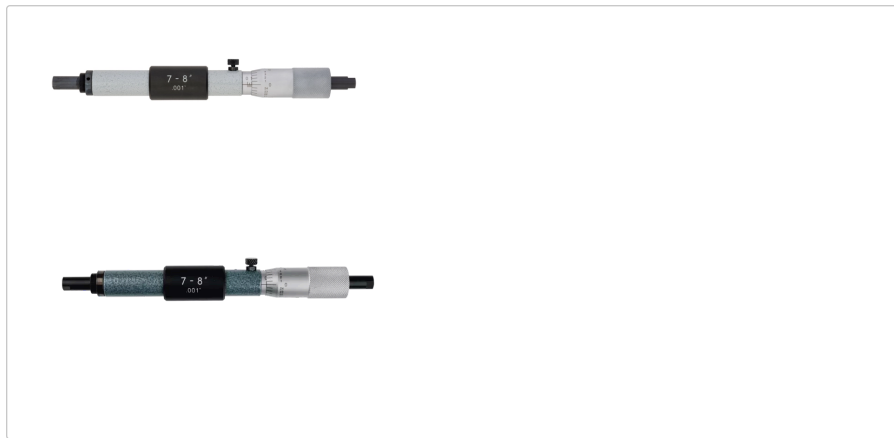

Description

This is a standard single rod type inside micrometer (individual unit), with the following features:

- Standard single rod.
- Carbide measuring faces.

Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Range:	7 - 8 "
Graduation:	0.001"
Max. Permissible Error J MPE:	±0.00025"
Scale:	Thimble and sleeve satin chrome finish, Ø18 mm
Measuring spindle:	With spindle lock (except 50-75 mm), spindle pitch 0,5 mm
Measuring face:	Carbide tipped
Measuring method:	2-point
Delivered:	Including box and spanner
Mass:	180 g

Dimensions

