


Tubular Inside Micrometer with Extension

Item number: 140-160

Images

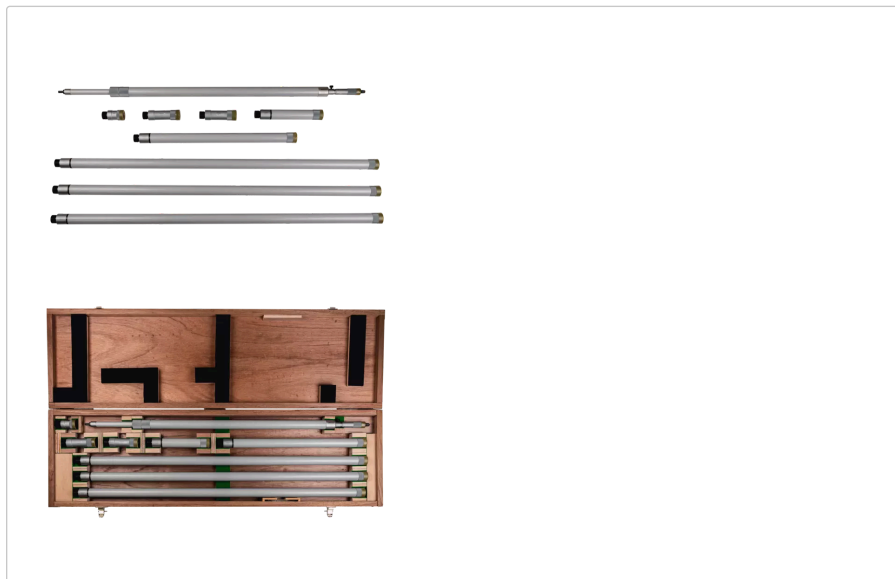

Description

A Mitutoyo inside micrometer covering a range of measurement by using a set of interchangeable extension tubes that can be used singly or in combination. The micrometer head is satin-chrome finished.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	1,000 - 5,000 mm
Measuring span:	50 mm
Graduation:	0.01 mm
Spindle feed error:	6 μ m
Limit of error:	$\pm(7+\text{number of rods}+\text{max. measurement length}/50) \mu\text{m}$
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring spindle:	Spindle pitch 0,5 mm
Measuring face:	Carbide
Extension rods:	8 (50, 100 (2 pcs.) 200, 500, 1000 mm (3 pcs.))
Delivered:	Including box, spanner, extension rods (8 pcs.), micrometer head
Mass:	8260 g

Dimensions

Spare parts

Consumable spares:



Extension Rod 50mm, for Series 140

Art No. 04GZA394
Suggested retail price: 118.00 €*



Extension Rod 100mm, for Series 140

Art No. 04GZA396
Suggested retail price: 149.00 €*



Extension Rod 200mm, for Series 140

Art No. 04GZA398
Suggested retail price: 214.00 €*



Extension Rod 500mm, for Series 140

Art No. 04GZA400
Suggested retail price: 380.00 €*



Extension Rod 1000mm, for Series 140

Art No. 04GZA402
Suggested retail price: 529.00 €*
