

Inside Micrometer, Interchangeable Rods

Item number: 141-211

Images



Description


This is an interchangeable rod type inside micrometer that offers you the following benefits:

- Interchangeable measuring rods and spacers achieve the full specified measuring range.
- Each interchangeable rod is marked with its measuring range.
- An extension handle to help you measure deep bores is included in sets up to 300 mm range.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	50 - 200 mm
Measuring span:	13 mm
Graduation:	0.01 mm
Scale:	Thimble and sleeve satin chrome finish
Measuring spindle:	Spindle pitch 0,5 mm with spindle lock
Measuring face:	Carbide
Measuring method:	2-point
Extension collar:	1 (12 mm) mm
Interchangeable rod:	3 (100, 150, 200 mm) mm
Accessories: inside micrometer (standard in the set) No.:	141-027
Delivered:	Including box, extension rods (3 pcs), extension collar, micrometer head 141-027
Mass:	125 g

Dimensions

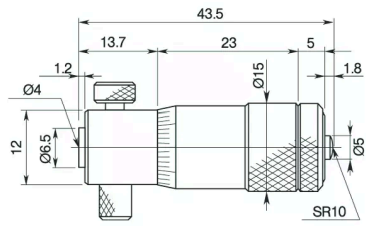

Accessories

Standard accessories:



Inside Micrometer, Interchangeable Rods

50-63mm, Carbide Tipped

Art No. 141-027

Suggested retail price: 137.00 €*