

Inside Micrometer, Interchangeable Rods

Item number: 141-215

Images



Description


This is an interchangeable rod type inside micrometer that offers you the following benefits:

- Interchangeable measuring rods and spacers achieve the full specified measuring range.
- Each interchangeable rod is marked with its measuring range.
- An extension handle to help you measure deep bores is included in sets up to 300 mm range.

Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Range:	2 - 12 "
Graduation:	0.001"
Head adjustment range:	0.5" mm
Scale:	Thimble and sleeve satin chrome finish
Measuring spindle:	Spindle pitch 0,635 mm with spindle lock
Measuring face:	Carbide
Measuring method:	2-point
Extension collar:	1 (0.5") mm
Interchangeable rod:	5 (2") mm
Accessories: inside micrometer (standard in the set) No.:	141-028
Delivered:	Including box, extension rods (5 pcs), extension collar, micrometer head 141-028
Mass:	275 g

Dimensions

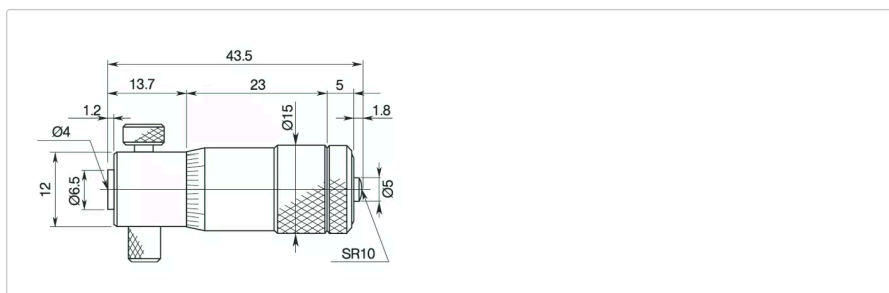

Standard accessories:



**Inside Micrometer,
Interchangeable Rods**

2-2,5", Carbide Tipped

Art No. 141-028

Suggested retail price: 137.00 €*
