


Caliper Jaw Micrometer

Item number: 143-103

Images

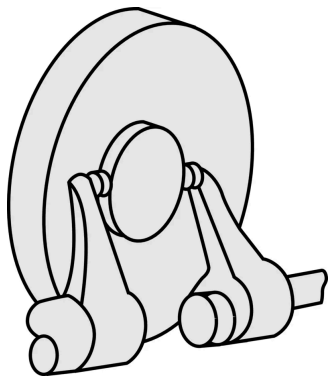

Description

A Mitutoyo non-digital micrometer provided with caliper jaws to enable measurement in confined spaces. A ratchet stop guarantees repeatable measurement.


Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	50 - 75 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	$\pm 7 \mu\text{m}$
Delivered:	Including box, spanner, setting standard
Flatness:	0,3 μm
Parallelism:	4 μm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	$\varnothing 8$ mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	1 - 6 N

Mass:

280 g

Dimensions

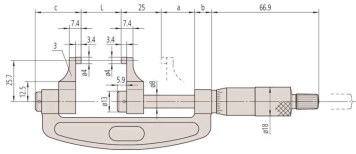

L: 50 mm

a: 31,8 mm

b: 10.6 mm

c: 28.6 mm

Accessories

Optional accessories:

Promotion!



Micrometer Stand, Adjustable Angle Type
for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: **56.00 €***
~~Suggested retail price: 70.00 €*~~

Standard accessories:



Micrometer Setting Standard

Length: 50mm

Art No. 167-102

Suggested retail price: 36.00 €*