


Caliper Jaw Micrometer

Item number: 143-108

Images

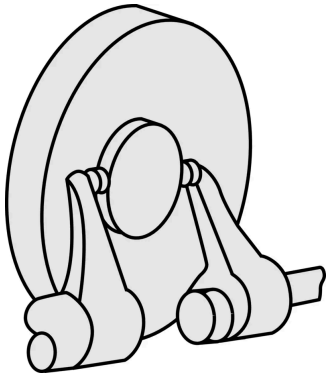

Description

This Caliper Jaw Micrometer has been specially designed for measuring in hard-to-reach places.

Features

Digital/Analog:	Analog
Delivered:	Including box, spanner, setting standard
Inch-Metric:	Metric
Range:	175 - 200 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	$\pm 10 \mu\text{m}$
Flatness:	0,3 μm
Parallelism:	5 μm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	$\varnothing 8$ mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	1 - 6 N

