


## Caliper Jaw Micrometer

Item number: 143-109

### Images

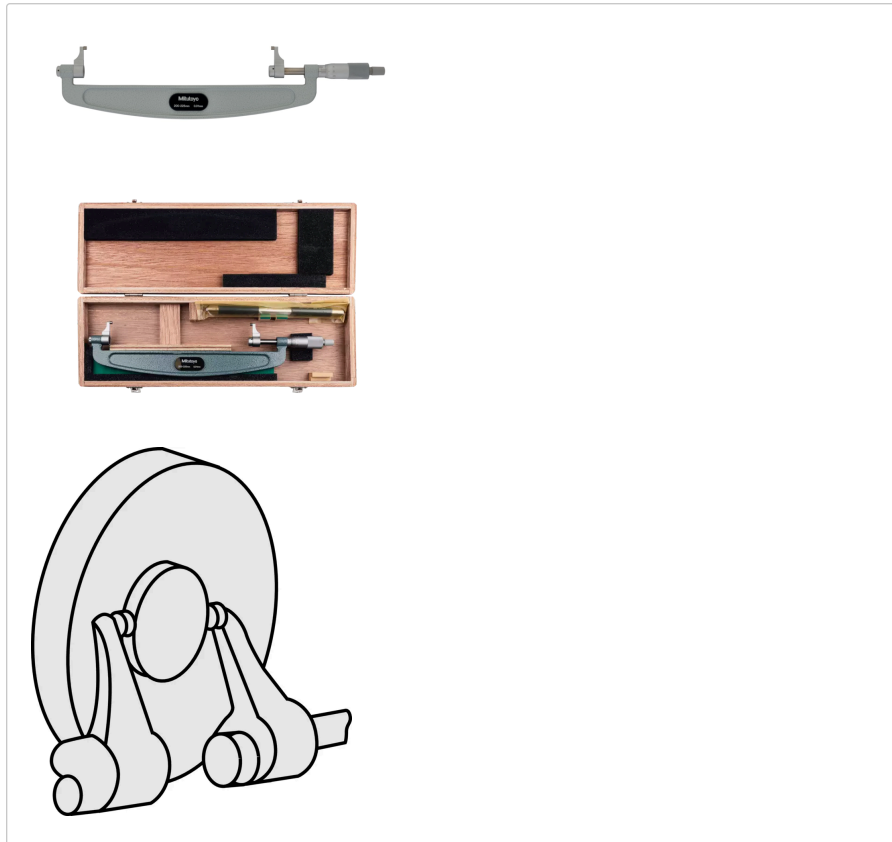

### Description

This Caliper Jaw Micrometer has been specially designed for measuring in hard-to-reach places.

### Features

<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, spanner, setting standard
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	200 - 225 mm
<b>Graduation:</b>	0,01 mm
<b>Max. Permissible Error J MPE:</b>	$\pm 11 \mu\text{m}$
<b>Flatness:</b>	0,3 $\mu\text{m}$
<b>Parallelism:</b>	6 $\mu\text{m}$
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	$\varnothing 8 \text{ mm}$ , spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$
<b>Measuring force:</b>	1 - 6 N
<b>Mass:</b>	690 g

### Dimensions

