


# Caliper Jaw Micrometer

Item number: 143-110

## Images

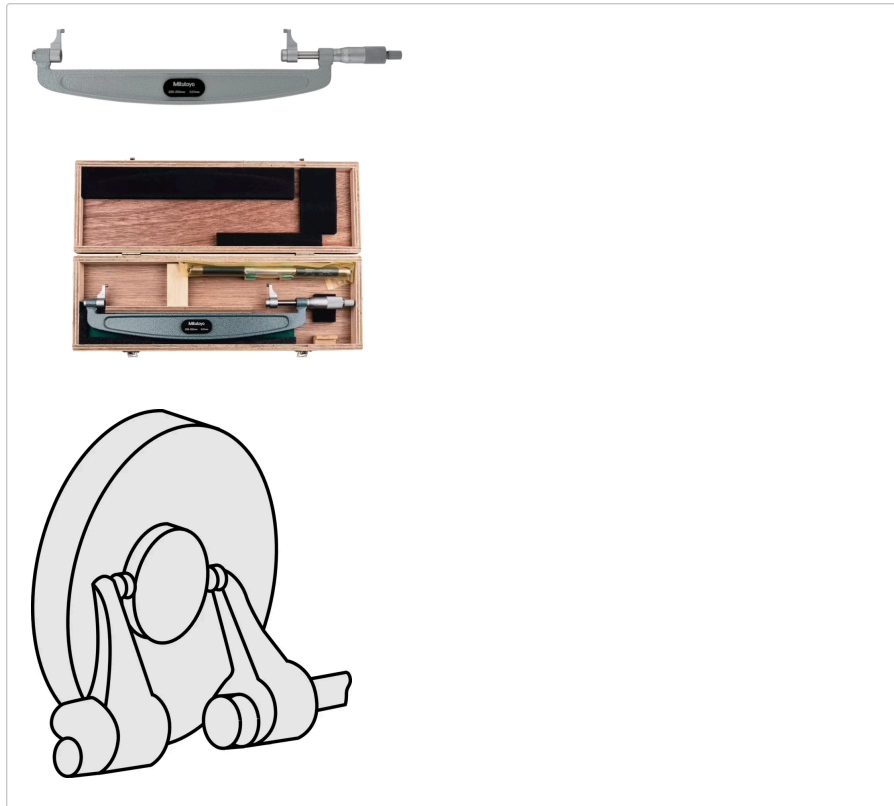

## Description

This Caliper Jaw Micrometer has been specially designed for measuring in hard-to-reach places.

## Features

<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, spanner, setting standard
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	225 - 250 mm
<b>Graduation:</b>	0,01 mm
<b>Max. Permissible Error J MPE:</b>	±11 µm
<b>Flatness:</b>	0,3 µm
<b>Parallelism:</b>	6 µm
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	ø8 mm, spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø18 mm
<b>Measuring force:</b>	1 - 6 N
<b>Mass:</b>	790 g

## Dimensions

