


## Caliper Jaw Micrometer

Item number: 143-111

### Images

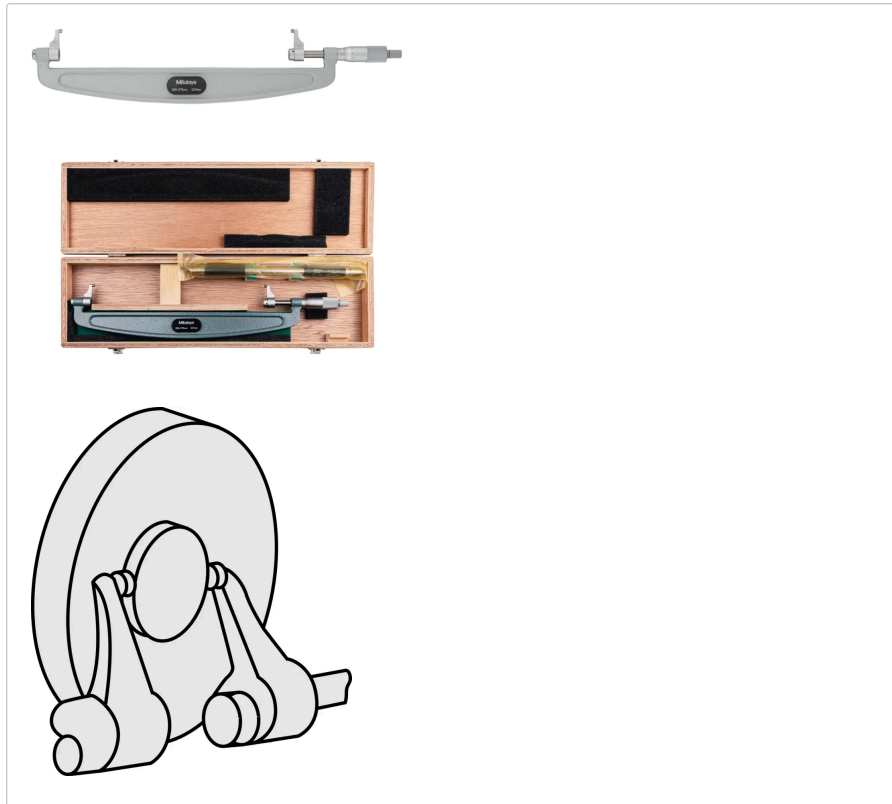

### Description

This Caliper Jaw Micrometer has been specially designed for measuring in hard-to-reach places.

### Features

|                                      |   |
|--------------------------------------|---|
| <b>Digital/Analog:</b>               | Analog  |
| <b>Delivered:</b>                    | Including box, spanner, setting standard                            |
| <b>Inch-Metric:</b>                  | Metric  |
| <b>Range:</b>                        | 250 - 275 mm  |
| <b>Graduation:</b>                   | 0,01 mm   |
| <b>Max. Permissible Error J MPE:</b> | $\pm 12 \mu\text{m}$  |
| <b>Flatness:</b>                     | 0,3 $\mu\text{m}$   |
| <b>Parallelism:</b>                  | 6 $\mu\text{m}$   |
| <b>Measuring face:</b>               | Carbide-tipped, micro-lap finish                                    |
| <b>Measuring spindle:</b>            | $\varnothing 8 \text{ mm}$ , spindle pitch 0,5 mm                   |
| <b>Scale:</b>                        | Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$ |
| <b>Measuring force:</b>              | 1 - 6 N   |
| <b>Mass:</b>                         | 900 g   |

### Dimensions

