


Caliper Jaw Micrometer

Item number: 143-121

Images

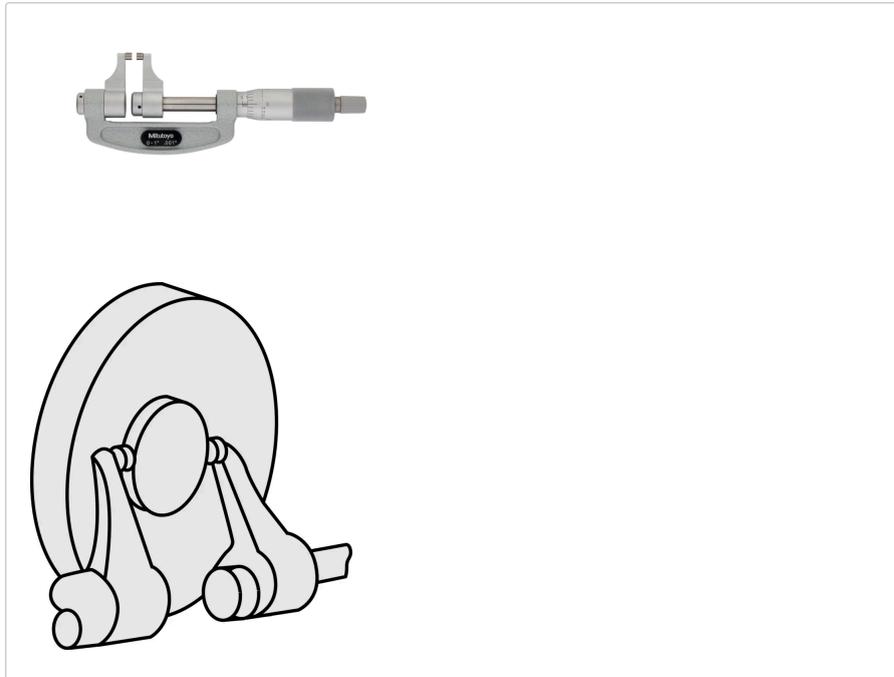


Description

A Mitutoyo non-digital micrometer provided with caliper jaws to enable measurement in confined spaces. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0 - 1 "
Graduation:	0,001"
Max. Permissible Error J MPE:	$\pm 0.00025"$
Delivered:	Including box, spanner
Flatness:	0.000012"
Parallelism:	0.00012"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	$\varnothing 8$ mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	1 - 6 N
Mass:	210 g

Dimensions

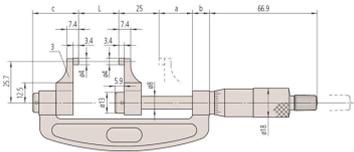

L: 59,8 mm

a: 31,8 mm

b: 10,6 mm

c: 28,6 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: 70.00 €*