


Caliper Jaw Inside Micrometer

Item number: 145-191

Images

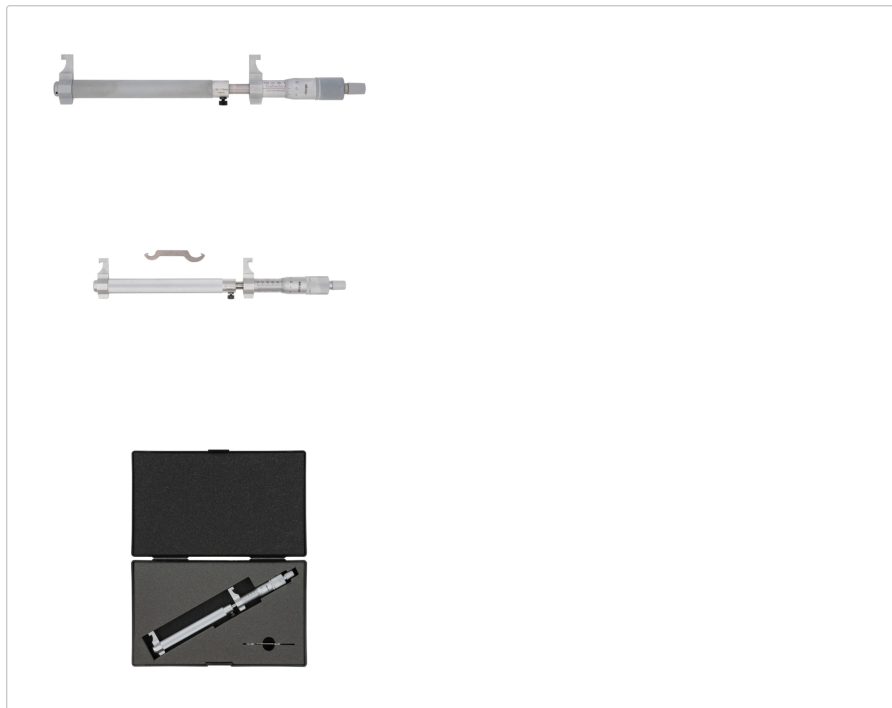

Description


The Caliper Jaw Inside Micrometer offers you the following benefits:

- Carbide measuring faces
- A setting standard (optional) is needed to accurately set the micrometer to the reference point.

Features


Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	150 - 175 mm
Graduation:	0,01 mm
Measuring force:	1-6 N
Max. Permissible Error J MPE:	$\pm 10 \mu\text{m}$
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$
Measuring spindle:	With spindle lock, spindle pitch 0,5 mm
Measuring face:	Carbide tipped
Delivered:	Including box, spanner, setting standard is not included
Mass:	250 g

Dimensions

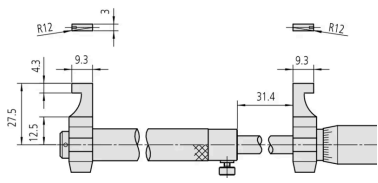

Accessories

Optional accessories:

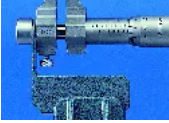

Holder for Series 145

Art No. 300400
Price on application



Cap for Series 145

Art No. 300401
Price on application