


Caliper Jaw Inside Micrometer

Item number: 145-196

Images

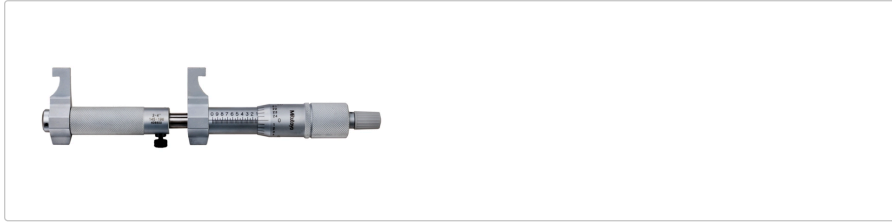

Description


The Caliper Jaw Inside Micrometer offers you the following benefits:

- Carbide measuring faces
- A setting standard (optional) is needed to accurately set the micrometer to the reference point.

Features

| | |
|--------------------------------------|--|
| Inch-Metric: | Inch |
| Digital/Analog: | Analog |
| Range: | 3 - 4 " |
| Graduation: | 0,001" |
| Measuring force: | 1-6 N |
| Max. Permissible Error J MPE: | ±0.0004" |
| Scale: | Thimble and sleeve satin chrome finish, ø18 mm |
| Measuring spindle: | With spindle lock, spindle pitch 0,635 mm |
| Measuring face: | Carbide tipped |
| Delivered: | Including box, spanner, setting standard is not included |
| Mass: | 180 g |

Dimensions

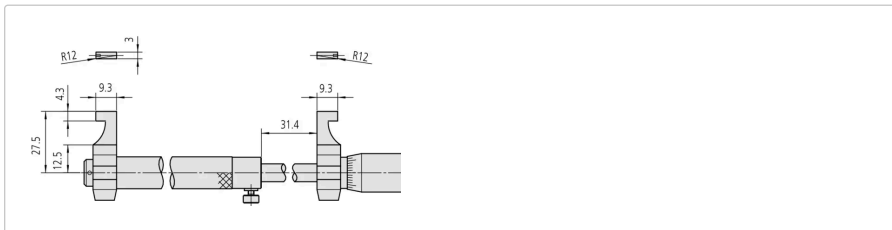


Accessories

Optional accessories:

Holder for Series 145

Art No. 300400

Price on application

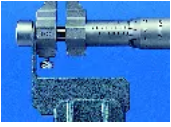

Cap for Series 145

Art No. 300401

Price on application

