

Caliper Jaw Inside Micrometer

Item number: 145-220

Images



Description


The Caliper Jaw Inside Micrometer offers you the following benefits:

- Carbide measuring faces
- A setting standard (optional) is needed to accurately set the micrometer to the reference point.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	275 - 300 mm
Graduation:	0,01 mm
Measuring force:	1-6 N
Max. Permissible Error J MPE:	$\pm 12 \mu\text{m}$
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$
Measuring spindle:	With spindle lock, spindle pitch 0,5 mm
Measuring face:	Carbide tipped
Delivered:	Including box, spanner, setting standard is not included
Mass:	370 g

Dimensions

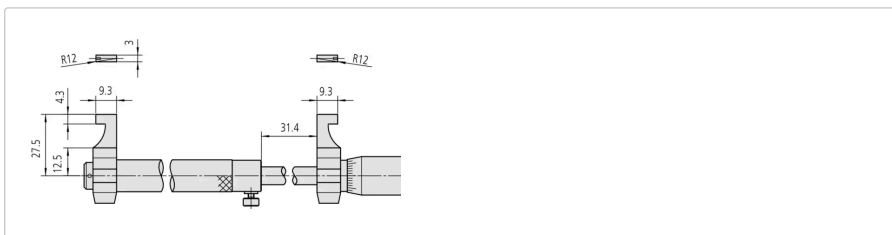

Accessories

Optional accessories:

Holder for Series 145

Art No. 300400

Price on application



Cap for Series 145

Art No. 300401

Price on application

