

Micrometer Head, Short Thimble Type

Item number: 148-312-10

Images




Description

Short thimble type with thimble diameter options.

Features

Digital/Analog:	Analog
Delivered:	In a paper box with spanner 301336
Inch-Metric:	Metric
Range:	0 - 13 mm
Graduation:	0.01 mm
Max. Permissible Error J MPE:	$\pm 2 \mu\text{m}$
Spindle end:	Flat
Spindle pitch:	0,5 mm
Stem \emptyset:	9.5 mm
Stem:	w/ clamp nut
Fixture thickness for clamp nut:	6 mm
Measuring face:	Hardened steel (> 60 HRC)
Thimble \emptyset:	29 mm
Mass:	103 g

Dimensions

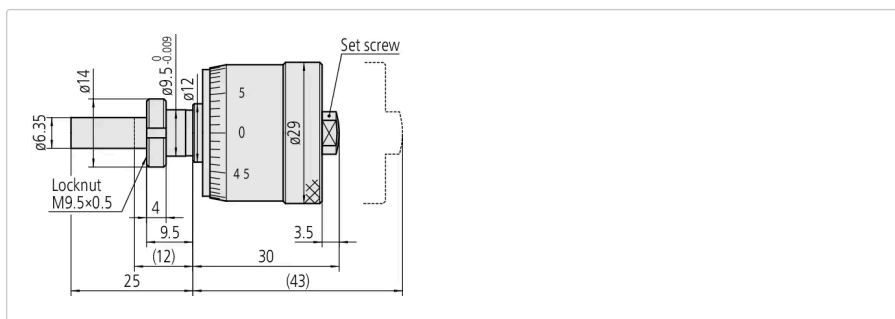

Accessories

Optional accessories:



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303559
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303568
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303563
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303572
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303561
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303570
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303565
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303574
Suggested retail price: 46.00 €*
