


Micrometer Head Zero Adjustable

Item number: 148-507

Images

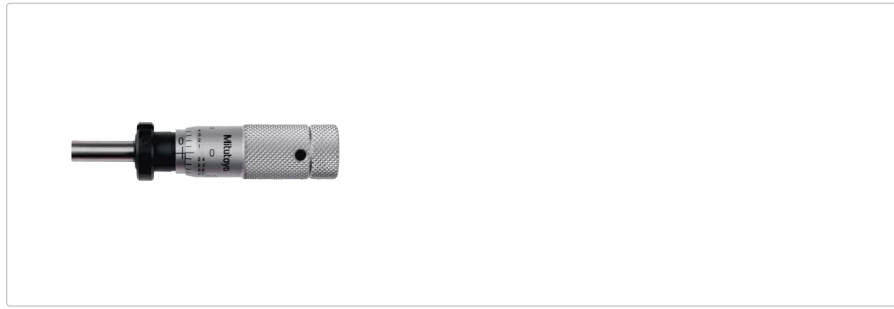

Description

These are a standard type of small size micrometer heads with a zero-adjustable thimble.

They offer the following benefits:

- You can make a zero-setting at any position by loosening the setscrew in the thimble.

Features

Digital/Analog:	Analog
Delivered:	In a paper box with hex wrench 202863, spanner 301336
Inch-Metric:	Inch
Range:	0 - 0.5 "
Graduation:	0.001"
Max. Permissible Error J MPE:	±0.0001"
Spindle end:	Flat
Spindle pitch:	0,5 mm
Stem Ø:	0.375"
Stem:	w/ clamp nut
Fixture thickness for clamp nut:	6 mm
Measuring face:	Hardened steel (>60 HRC)
Mass:	50 g

Dimensions

