


Micrometer Head, Small Standard Type

Item number: 148-812-10

Images

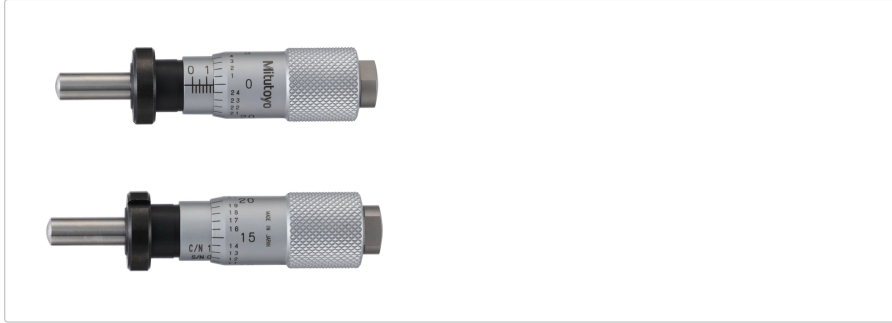

Description

This is a standard, small-sized micrometer head which offers you the following benefits:

- Plain stem and a flat or spherical spindle end
- Hardened steel measuring surface

Features

Digital/Analog:	Analog
Delivered:	In a paper box with spanner 301336
Inch-Metric:	Inch
Range:	0 - 0.5 "
Graduation:	0.001"
Max. Permissible Error J MPE:	±0.0001"
Spindle end:	Spherical (SR4)
Spindle pitch:	0.5 mm
Stem Ø:	0.375"
Stem:	w/ clamp nut
Fixture thickness for clamp nut:	6 mm
Measuring face:	Hardened steel (> 60 HRC)
Mass:	35 g