

Micrometer Head Zero Adjustable

Item number: 148-853

Images




Description

A small, standard, zero-adjustable non-digital Mitutoyo micrometer head with plain 9.5mm stem and spherically radiused spindle tip.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	0 - 13 mm
Graduation:	0.01 mm
Max. Permissible Error J MPE:	±2 μm
Spindle end:	Spherical (SR4)
Spindle pitch:	0,5 mm
Stem Ø:	9.5 mm
Stem:	Plain
Delivered:	In a paper box with hex wrench 202863
Measuring face:	Hardened steel (>60 HRC)
Mass:	40 g

Dimensions

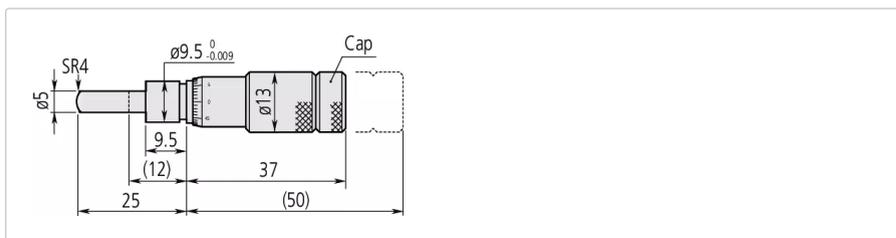

Accessories

Optional accessories:



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303560
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303569
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303564
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303573
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303562
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303571
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303566
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303575
Suggested retail price: 46.00 €*
