

Micrometer Head Zero Adjustable

Item number: 148-866

Images



Description

These are a standard type of small size micrometer heads with a zero-adjustable thimble.


They offer the following benefits:

- You can make a zero-setting at any position by loosening the setscrew in the thimble.

Features

Digital/Analog:	Analog
Delivered:	In a paper box with hex wrench 202863
Inch-Metric:	Metric
Range:	0 - 13 mm
Graduation:	0.01 mm
Max. Permissible Error J MPE:	$\pm 2 \mu\text{m}$
Spindle end:	Flat
Spindle pitch:	0,5 mm
Stem \varnothing:	9.5 mm
Stem:	Plain
Special features:	Reverse reading
Measuring face:	Hardened steel (>60 HRC)
Mass:	35 g

Dimensions

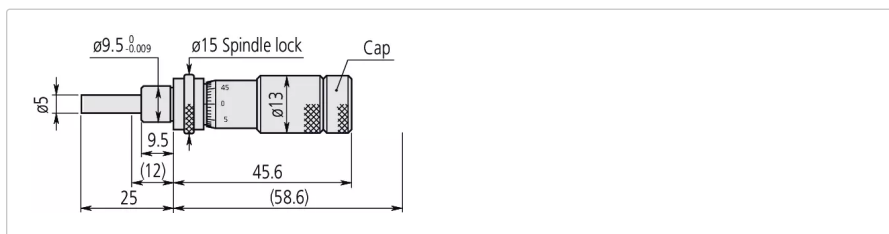

Accessories

Optional accessories:




Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303560
Suggested retail price: 43.00 €*




Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303569
Suggested retail price: 46.00 €*

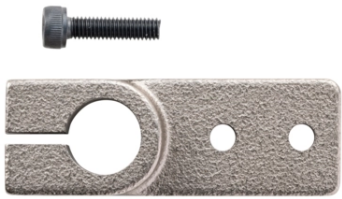


Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303564
Suggested retail price: 43.00 €*

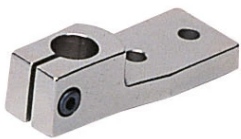

Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303573
Suggested retail price: 46.00 €*

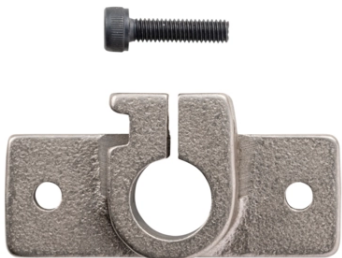

Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303562
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303571
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303566
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303575
Suggested retail price: 46.00 €*
