

Micrometer Head Zero Adjustable

Item number: 148-868

Images



Description

These are a standard type of small size micrometer heads with a zero-adjustable thimble.


They offer the following benefits:

- You can make a zero-setting at any position by loosening the setscrew in the thimble.

Features

Digital/Analog:	Analog
Delivered:	In a paper box with hex wrench 202863, spanner 301336
Inch-Metric:	Metric
Range:	0 - 13 mm
Graduation:	0.01 mm
Max. Permissible Error J MPE:	$\pm 2 \mu\text{m}$
Spindle end:	Flat
Spindle pitch:	0,5 mm
Stem \varnothing:	9.5 mm
Stem:	w/ clamp nut
Fixture thickness for clamp nut:	6 mm
Special features:	Reverse reading
Measuring face:	Hardened steel (>60 HRC)
Mass:	40 g

Dimensions

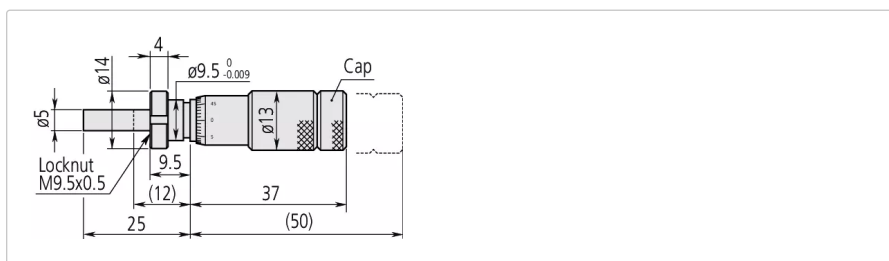

Accessories

Optional accessories:



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303559
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303568
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303563
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303572
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303561
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303570
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303565
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303574
Suggested retail price: 46.00 €*
