


Micrometer Head Carbide-Tipped

Item number: 149-184

Images

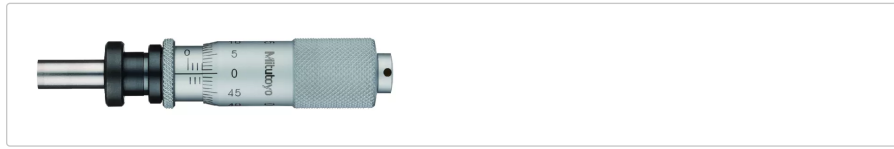


Description

A small, standard, non-digital Mitutoyo micrometer head with M9.5 clamp-nut stem, flat tungsten-carbide spindle tip and concentric spindle lock.

Features

Model:	MHM2-15L
Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	0 - 15 mm
Graduation:	0,01mm
Max. Permissible Error J MPE:	±2 μm
Spindle end:	Flat
Spindle pitch:	0,5 mm
Stem Ø:	9.5 mm
Stem:	w/ clamp nut
Fixture thickness for clamp nut:	6 mm
Delivered:	In a paper box with spanner 200168
Measuring face:	Carbide-tipped
Mass:	60 g

Dimensions

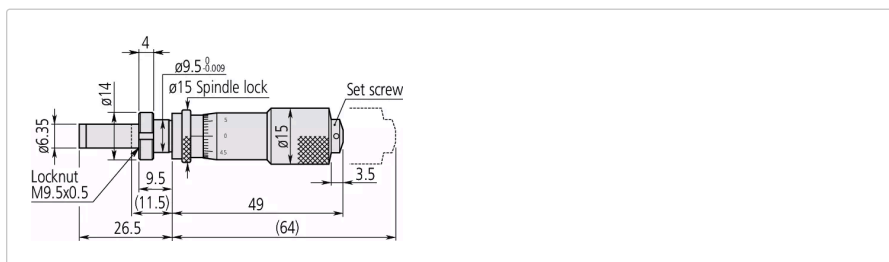

Accessories

Optional accessories:



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303559
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303568
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303563
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303572
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303561
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303570
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303565
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303574
Suggested retail price: 46.00 €*
