


Micrometer Head, Carbide Tipped Spindle

Item number: 149-822-10

Images

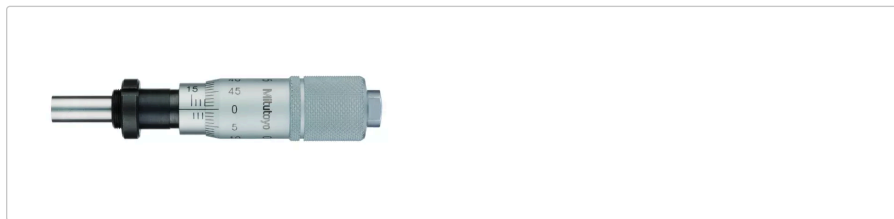

Description

This small micrometer head with tungsten carbide measuring surface offers you the following benefits:

- Stem with clamp nut and a flat or spherical spindle end
- Stem with carbide-tipped spindle

Features

Digital/Analog:	Analog
Delivered:	In a paper box with spanner 200168
Inch-Metric:	Metric
Range:	0 - 15 mm
Graduation:	0.01 mm
Max. Permissible Error J MPE:	±2 μm
Spindle end:	Flat
Spindle pitch:	0.5 mm
Stem Ø:	9.5 mm
Stem:	w/ clamp nut
Fixture thickness for clamp nut:	11.5 mm
Special features:	Reverse reading
Measuring face:	Carbide tipped (>90 HRA)
Mass:	60 g

Dimensions



Accessories

Optional accessories:



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303559
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303568
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303563
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303572
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303561
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303570
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303565
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303574
Suggested retail price: 46.00 €*
