

Micrometer Head, Medium-sized Standard

Item number: 150-190

Images




Description

A medium sized, standard, high resolution, non-digital Mitutoyo micrometer head with plain \varnothing 10mm stem and flat tungsten-carbide spindle tip.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Graduation:	0,001 mm
Range:	0 - 25 mm
Max. Permissible Error J MPE:	$\pm 2 \mu\text{m}$
Spindle end:	Flat
Spindle pitch:	0,5 mm
Stem \varnothing:	10 mm
Stem:	Plain
Special features:	Graduation 0.001 mm
Delivered:	In a paper box with spanner 301336
Measuring face:	Carbide-tipped
Mass:	95 g

Dimensions

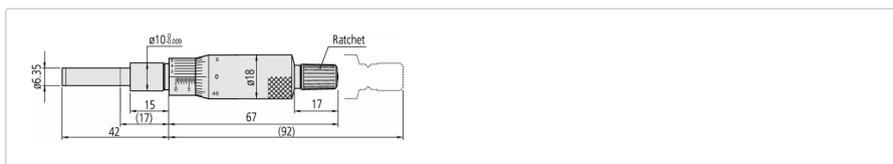

Accessories

Optional accessories:



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
 Art No. 303579
 Suggested retail price: 50.00 €*



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303583
Suggested retail price: 50.00 €*



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303581
Suggested retail price: 50.00 €*



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303585
Suggested retail price: 50.00 €*
