

# Micrometer Head, Medium-sized Type

Item number: 150-195-10

## Images



## Description


This is a standard, medium-size micrometer head that offers you the following benefits:

- Plain stem and a flat or spherical spindle end
- With carbide-tipped spindle

## Features


<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	In a paper box with spanner 301336
<b>Inch-Metric:</b>	Metric
<b>Graduation:</b>	0.01 mm
<b>Range:</b>	0 - 25 mm
<b>Max. Permissible Error J MPE:</b>	$\pm 2 \mu\text{m}$
<b>Spindle end:</b>	Flat
<b>Spindle pitch:</b>	0.5 mm
<b>Stem <math>\varnothing</math>:</b>	10 mm
<b>Stem:</b>	w/ clamp nut
<b>Fixture thickness for clamp nut:</b>	11.5 mm
<b>Special features:</b>	w/o ratchet stop
<b>Measuring face:</b>	Carbide tipped (>90 HRA)
<b>Mass:</b>	90 g

## Dimensions

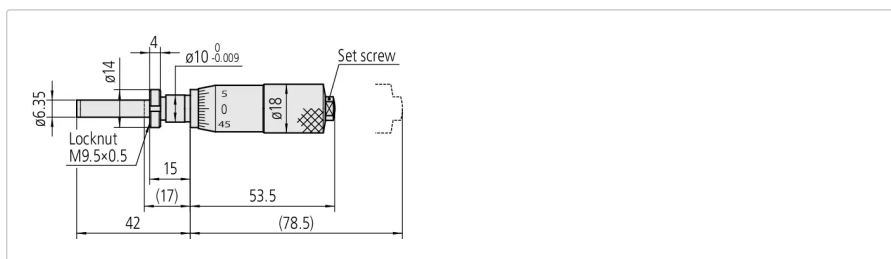

## Accessories

Optional accessories:

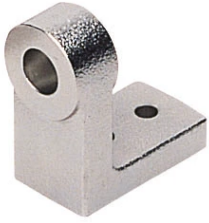

### Fixture for Micrometer Head, Clamp Nut

for 10mm Stem  
Art No. 303578  
Suggested retail price: 50.00 €\*  

---



### Fixture for Micrometer Head, Clamp Nut

for 10mm Stem  
Art No. 303582  
Suggested retail price: 50.00 €\*  


---



### Fixture for Micrometer Head, Clamp Nut

for 10mm Stem  
Art No. 303580  
Suggested retail price: 50.00 €\*  

---

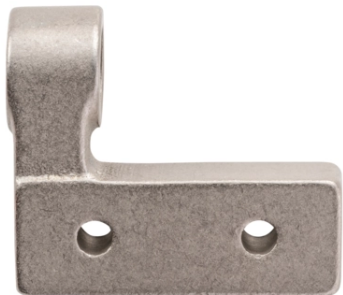

### Fixture for Micrometer Head, Clamp Nut

for 10mm Stem  
Art No. 303584  
Suggested retail price: 50.00 €\*  

---