

Micrometer Head, Medium-sized Standard

Item number: 150-802

Images




Description

A medium sized, standard, non-digital Mitutoyo micrometer head with M9.5 clamp-nut stem and spherically radiused tungsten-carbide spindle tip.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Graduation:	0,01 mm
Range:	0 - 25 mm
Max. Permissible Error J MPE:	±2 µm
Spindle end:	Spherical (SR4)
Spindle pitch:	0,5 mm
Stem Ø:	10 mm
Stem:	w/ clamp nut
Fixture thickness for clamp nut:	11.5 mm
Delivered:	In a paper box with spanner 301336
Measuring face:	Carbide-tipped
Mass:	100 g

Dimensions

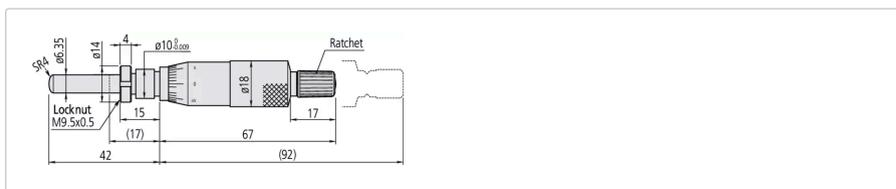

Accessories

Optional accessories:



Fixture for Micrometer Head, Clamp Nut

for 10mm Stem
Art No. 303578
Suggested retail price: 50.00 €*




Fixture for Micrometer Head, Clamp Nut

for 10mm Stem
Art No. 303582
Suggested retail price: 50.00 €*



Fixture for Micrometer Head, Clamp Nut

for 10mm Stem
Art No. 303580
Suggested retail price: 50.00 €*

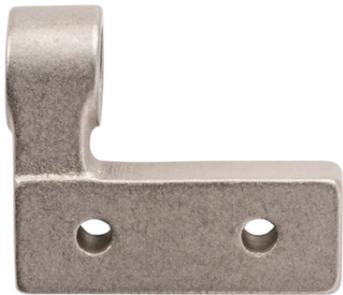

Fixture for Micrometer Head, Clamp Nut

for 10mm Stem
Art No. 303584
Suggested retail price: 50.00 €*
