

Micrometer Head, Medium-sized Standard

Item number: 150-823

Images



Description


This is a standard, medium-size micrometer head that offers you the following benefits:

- Plain stem and a flat or spherical spindle end
- With carbide-tipped spindle

Features

Digital/Analog:	Analog
Delivered:	In a paper box with spanner 301336
Inch-Metric:	Metric
Graduation:	0,01 mm
Range:	0 - 25 mm
Max. Permissible Error J MPE:	±2 μm
Spindle end:	Flat
Spindle pitch:	0,5 mm
Stem Ø:	10 mm
Stem:	Plain
Special features:	Reverse reading
Measuring face:	Hardened steel (>60 HRC)
Mass:	125 g

Dimensions

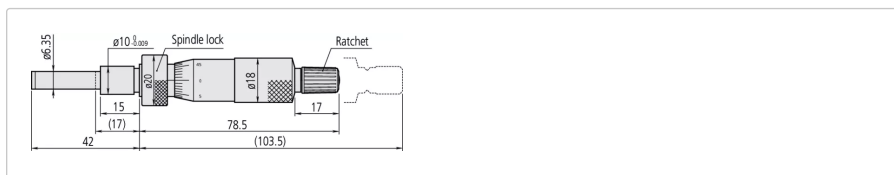

Accessories

Optional accessories:



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303579
Suggested retail price: 50.00 €*



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303583
Suggested retail price: 50.00 €*



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303581
Suggested retail price: 50.00 €*



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303585
Suggested retail price: 50.00 €*
