


Micrometer Head, Medium-sized Type

Item number: 151-243-10

Images

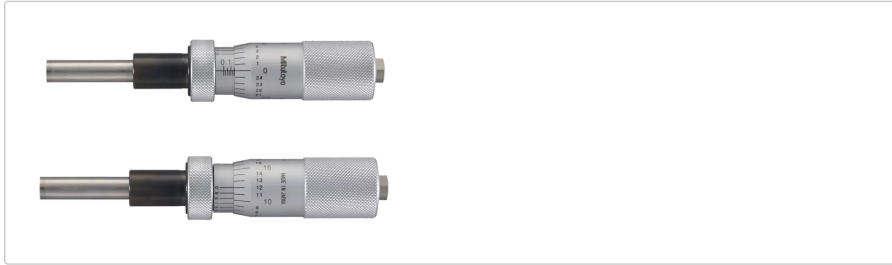

Description

These micrometer heads are a medium-sized, standard type.

They offer the following benefits:

- 8 mm diameter spindle
- Extremely sturdy micrometer head with or without a ratchet.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0 - 0,1 "
Graduation:	0.0001"
Max. Permissible Error J MPE:	±0.0001"
Spindle end:	Flat
Spindle pitch:	0,5 mm
Stem Ø:	0.5"
Stem:	Plain
Special features:	w/o ratchet stop
Delivered:	In a paper box
Measuring face:	Carbide tipped (>90 HRA)
Mass:	165 g