

Micrometer Head Non-rotating Spindle

Item number: 153-101

Images




Description

A non-digital, high resolution Mitutoyo micrometer head with plain ± 9.5 mm stem and non-rotating spindle fitted with flat tungsten-carbide tip.

Features

Model:	MHK-15
Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	0 - 15 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	$\pm 3 \mu\text{m}$
Spindle end:	Flat
Spindle pitch:	0,5 mm
Stem \varnothing:	9.5 mm
Stem:	Plain
Delivered:	In a paper box with spanner 200168
Measuring face:	Carbide tipped
Mass:	70 g

Dimensions

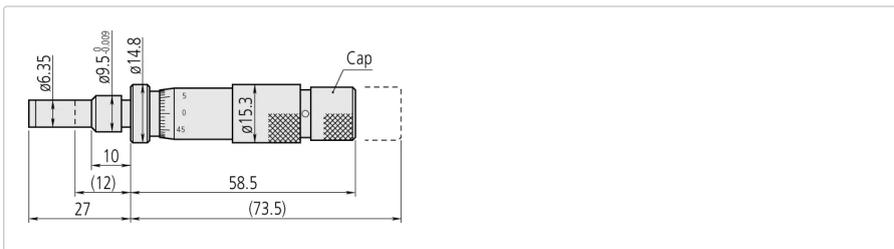

Accessories

Optional accessories:



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303560
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303569
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303564
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303573
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303562
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303571
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303566
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Plain Stem

for 9,5mm Stem
Art No. 303575
Suggested retail price: 46.00 €*
