


Vernier Caliper Nib Style Jaw

Item number: 160-102

Images

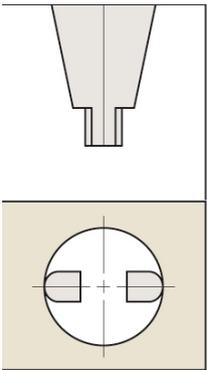

Description


These vernier calipers with nib style jaws come with or without fine adjustment. They offer you the following benefits:

- For the metric only models the top offset vernier scale allows you to directly read the inside dimensions without having to add the nib widths.
- Main scale and vernier scale satin chrome finish gives you high readability.

Features

With upper locking screw:	Yes
Range:	0 - 24 "
Graduation:	0,001"
Inside measuring from:	0.504"
Delivered:	In a box
Max. Permissible Error E MPE:	± 0.002 "
Max. Permissible Error S MPE:	± 0.002 "
Mass:	1400 g

Dimensions

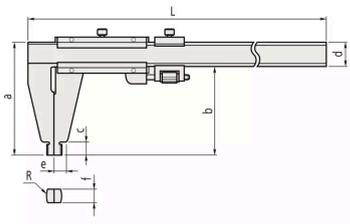

a: 125 mm

b: 100 mm

c: 18 mm

d: 25 mm

e: 14.8 mm

f: 6 mm

R: 10 mm