
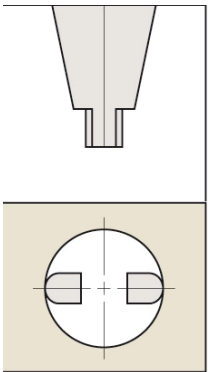


Vernier Caliper Nib Style Jaw

Item number: 160-124

Images

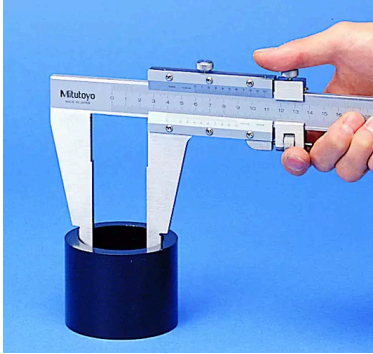

Description


These vernier calipers with nib style jaws come with or without fine adjustment. They offer you the following benefits:

- For the metric only models the top offset vernier scale allows you to directly read the inside dimensions without having to add the nib widths.
- Main scale and vernier scale satin chrome finish gives you high readability.

Features

With upper locking screw:	Yes
Range:	0 - 12 "
Graduation:	0,001"
Inside measuring from:	0.304"
Delivered:	In a box
Max. Permissible Error E MPE:	$\pm 0,0015$ "
Max. Permissible Error S MPE:	$\pm 0,0015$ "
Mass:	450 g

Dimensions

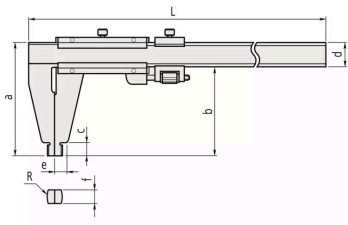

a: 95 mm

b: 25 mm

c: 12 mm

d: 20 mm

e: 10 mm

f: 3.8 mm

R: 5 mm

Accessories

Optional accessories:



Depth Base Attachment for Caliper

125mm width for 300mm Range

Art No. 050085-10

Suggested retail price: 74.00 €*