


Vernier Caliper Nib Style Jaw

Item number: 160-132

Images

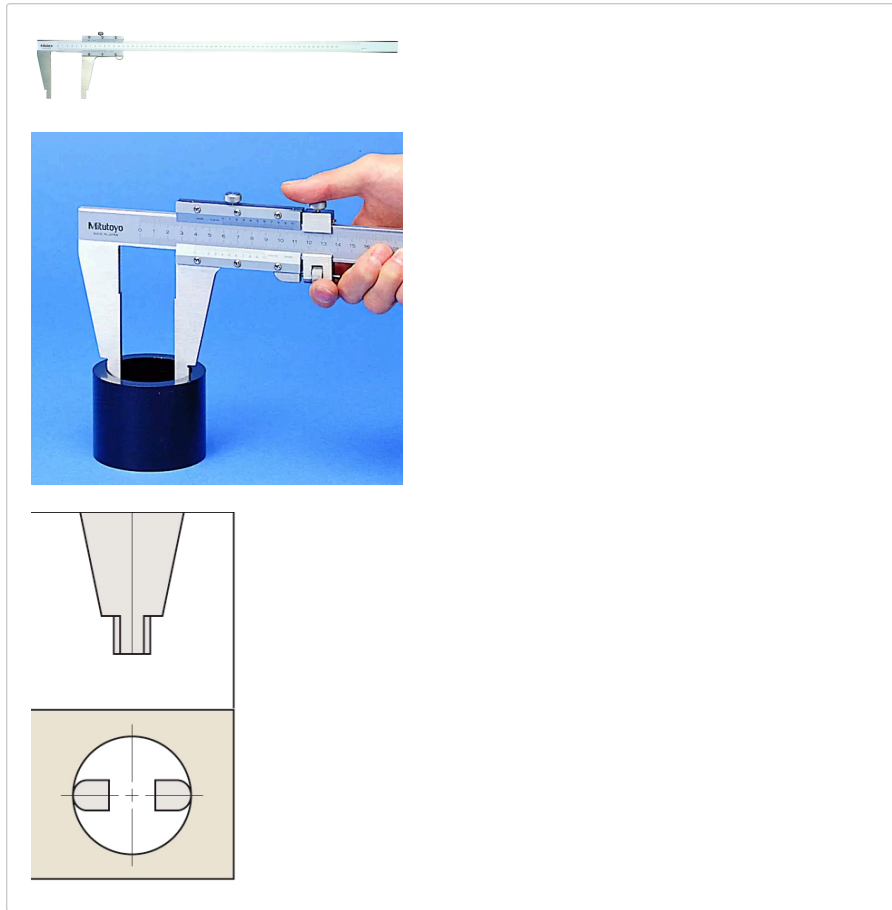

Description


These vernier calipers with nib style jaws come with or without fine adjustment. They offer you the following benefits:

- For the metric only models the top offset vernier scale allows you to directly read the inside dimensions without having to add the nib widths.
- Main scale and vernier scale satin chrome finish gives you high readability.

Features

With upper locking screw:	Yes
Range:	0 - 1,000 mm
Graduation:	0,05 mm
Inside measuring from:	20.1 mm
Delivered:	In a box
Max. Permissible Error E MPE:	$\pm 0,15$ mm
Max. Permissible Error S MPE:	$\pm 0,15$ mm
Mass:	3300 g

Dimensions

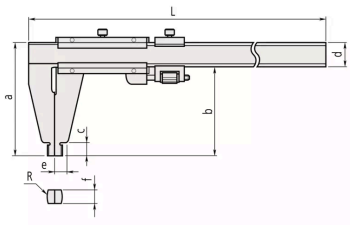

a: 172 mm

b: 140 mm

c: 24 mm

d: 32 mm

e: 17 mm

f: 8 mm

R: 10 mm